

**HDC-C-M20-BCG0.08-0.2AU****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Crimps provide a electrical and mechanical connection between wire and contact that is both secure and reliable. The optimal crimp connection is gas-tight and corrosion-resistant.

**General ordering data**

Version	Heavy-duty connectors, Crimp contact, CM 20, Female, Conductor cross-section, max.: 0.2, punched, Copper alloy
Order No.	<a href="#">1682430000</a>
Type	HDC-C-M20-BCG0.08-0.2AU
GTIN (EAN)	4008 190859954
Qty.	500 items

**HDC-C-M20-BCG0.08-0.2AU**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Net weight	0.22 g
------------	--------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**General data**

Contact diameter, male Ø	1 mm	Stripping length, rated connection	2.5 mm
Type of connection	Crimp connection	Version insert	CM 20
Volume resistance	≤5 mΩ	Conductor cross-section, max.	0.2 mm <sup>2</sup>
Conductor cross-section, min.	0.08 mm <sup>2</sup>	Surface finish	gold
Plugging cycles	≥ 500	Type	Female
Basic material	Copper alloy	Production methods	punched
Cross-section for connected wire	0.08 - 0.2 mm <sup>2</sup>	Material of contact	Copper alloy

**Classifications**


ETIM 8.0	EC000796	ETIM 9.0	EC000796
ETIM 10.0	EC000796	ECLASS 14.0	27-44-02-04
ECLASS 15.0	27-44-02-04		

## HDC-C-M20-BCG0.08-0.2AU

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany


## Drawings

[www.weidmueller.com](http://www.weidmueller.com)

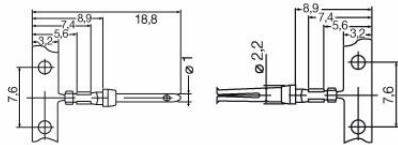

Leiterquerschnitt      Abisolierlänge

0,08 - 0,20 mm <sup>2</sup> AWG 28-24	2,5+0,5 mm
0,20 - 0,52 mm <sup>2</sup> AWG 24-20	2,5+0,5 mm

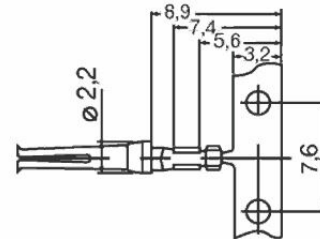

## HDC-C-M20-BCG0.08-0.2AU

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

# Accessories

### Slotted screwdriver



Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip

#### General ordering data

Type	SDS 0.6X3.5X100	Version	
Order No.	<a href="#">9008330000</a>	Screwdriver, Screwdriver	
GTIN (EAN)	4032248056286		
Qty.	1 ST		

### ... for SUB-D contacts



Crimping tools for SUB-D contacts

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation
- With end stop for exact positioning of the contacts

#### General ordering data

Type	HTF SUB-D	Version	
Order No.	<a href="#">9013260000</a>	Pressing tool, Crimping tool for contacts, FoderBcrimp	
GTIN (EAN)	4008190056896		
Qty.	1 ST		