


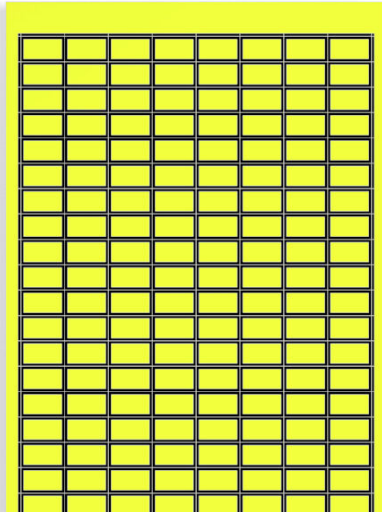

Similar to illustration



PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 11 x 19 mm, yellow
Order No.	1686170000
Type	PAGETAB 19/11
GTIN (EAN)	4008190492564
Qty.	25 items

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.0031 inch
Height	11 mm	Height (inches)	0.4331 inch
Width	19 mm	Width (inches)	0.748 inch
Net weight	8.62 g		

Temperatures

Operating temperature range	-29...93 °C
-----------------------------	-------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Adhesive	Permanent acrylic copolymer	
Material colour according to resistance code	4	
Number per sheet	200	
Version	Self-adhesive	
Width	19 mm	
Operating temperature range, max.	93 °C	
Operating temperature range, min.	-29 °C	
Colour	yellow	
Basic material	Acrylic-coated fibre webbing	
Printed characters	without	
Number of markers per packaging unit	5000	
Number of markers per packaging unit	Form of supply	Label sheet
	Number of combinations per packaging unit	25
	Number of markers per combination	200
Number of markers per combination	1 Label sheet = 200 Device markers	
Operating temperature range	-29...93 °C	
Imprint	Neutral	

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

