


**PAGETAB 19/11**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

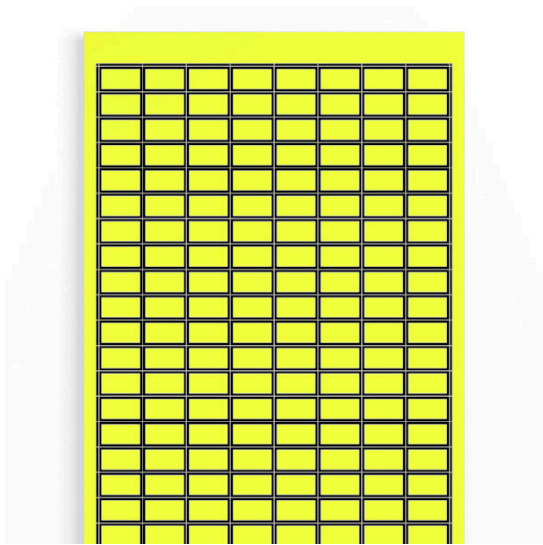

Similar to illustration

PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

**General ordering data**

Version	Device markers, Device markers, 11 x 19 mm, yellow
Order No.	<a href="#">1686170000</a>
Type	PAGETAB 19/11
GTIN (EAN)	4008190492564
Qty.	25 items

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.0031 inch
Height	11 mm	Height (inches)	0.4331 inch
Width	19 mm	Width (inches)	0.748 inch
Net weight	8.62 g		

**Temperatures**

Operating temperature range	-29...93 °C
-----------------------------	-------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**General data**

Adhesive	Permanent acrylic copolymer		
Material colour according to resistance code	4		
Number per sheet	200		
Version	Self-adhesive		
Width	19 mm		
Operating temperature range, max.	93 °C		
Operating temperature range, min.	-29 °C		
Colour	yellow		
Basic material	Acrylic-coated fibre webbing		
Printed characters	without		
Number of markers per packaging unit	5000		
Number of markers per packaging unit	Form of supply	Label sheet	
	Number of combinations per packaging unit	25	
	Number of markers per combination	200	
Number of markers per combination	1 Label sheet = 200 Device markers		
Operating temperature range	-29...93 °C		
Imprint	Neutral		

**Classifications**

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

**Drawings**

