


PAGETAB 38/11

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

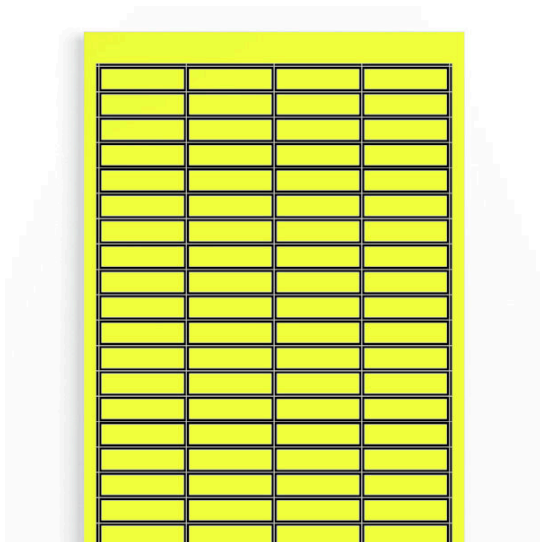

Similar to illustration

PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 11 x 38 mm, yellow
Order No.	1686200000
Type	PAGETAB 38/11
GTIN (EAN)	4008190492632
Qty.	25 items

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.0031 inch
Height	11 mm	Height (inches)	0.4331 inch
Width	38 mm	Width (inches)	1.4961 inch
Net weight	8.62 g		

Temperatures

Operating temperature range	-29...93 °C
-----------------------------	-------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Adhesive	Permanent acrylic copolymer		
Material colour according to resistance code	4		
Number per sheet	100		
Version	Self-adhesive		
Width	38 mm		
Operating temperature range, max.	93 °C		
Operating temperature range, min.	-29 °C		
Colour	yellow		
Basic material	Acrylic-coated fibre webbing		
Printed characters	without		
Number of markers per packaging unit	2500		
Number of markers per packaging unit	Form of supply	Label sheet	
	Number of combinations per packaging unit	25	
	Number of markers per combination	100	
Number of markers per combination	1 Label sheet = 100 Device markers		
Operating temperature range	-29...93 °C		
Imprint	Neutral		

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

