


PAGETAB 56/22

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

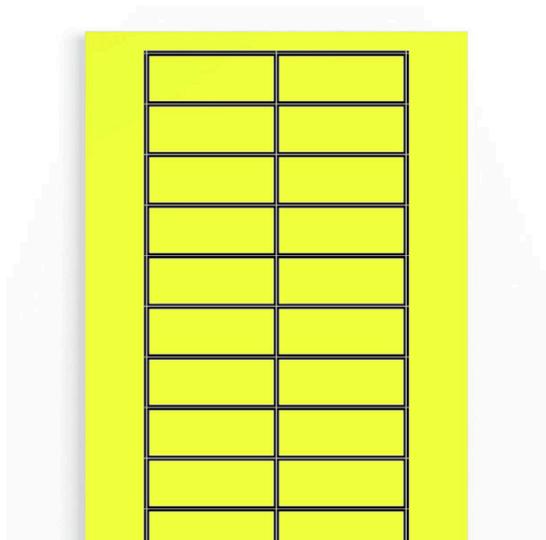

Similar to illustration



PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

General ordering data

Version	Device markers, Device markers, 22 x 56 mm, yellow
Order No.	1686210000
Type	PAGETAB 56/22
GTIN (EAN)	4008 190492649
Qty.	25 items

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	0.08 mm	Depth (inches)	0.0031 inch
Height	22 mm	Height (inches)	0.8661 inch
Width	56 mm	Width (inches)	2.2047 inch
Net weight	11.24 g		

Temperatures

Operating temperature range -29...93 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

Adhesive	Permanent acrylic copolymer		
Material colour according to resistance code	4		
Number per sheet	24		
Version	Self-adhesive		
Width	56 mm		
Operating temperature range, max.	93 °C		
Operating temperature range, min.	-29 °C		
Colour	yellow		
Basic material	Acrylic-coated fibre webbing		
Printed characters	without		
Number of markers per packaging unit	600		
Number of markers per packaging unit	Form of supply	Label sheet	
	Number of combinations per packaging unit	25	
	Number of markers per combination	24	
Number of markers per combination	1 Label sheet = 24 Device markers		
Operating temperature range	-29...93 °C		
Imprint	Neutral		

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

