


## PAGETAB 60/35

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

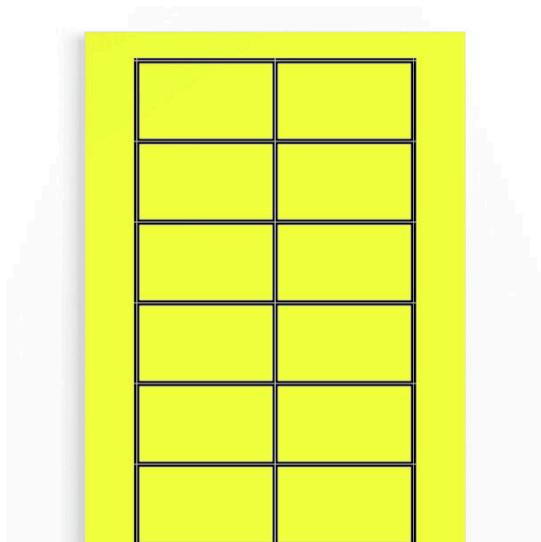

Similar to illustration



PageTab are woven-fabric labels in sheet form. Except for the 8 x 20 version, all labels have a black border.

### General ordering data

Version	Device markers, Device markers, 35 x 60 mm, yellow
Order No.	<a href="#">1686220000</a>
Type	PAGETAB 60/35
GTIN (EAN)	4008 190492656
Qty.	25 items

**PAGETAB 60/35**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	0.08 mm	Depth (inches)	0.0031 inch
Height	35 mm	Height (inches)	1.378 inch
Width	60 mm	Width (inches)	2.3622 inch
Net weight	8.88 g		

**Temperatures**

Operating temperature range -29...93 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

Adhesive	Permanent acrylic copolymer		
Material colour according to resistance code	4		
Number per sheet	16		
Version	Self-adhesive		
Width	60 mm		
Operating temperature range, max.	93 °C		
Operating temperature range, min.	-29 °C		
Colour	yellow		
Basic material	Acrylic-coated fibre webbing		
Printed characters	without		
Number of markers per packaging unit	400		
Number of markers per packaging unit	Form of supply	Label sheet	
	Number of combinations per packaging unit	25	
	Number of markers per combination	16	
Number of markers per combination	1 Label sheet = 16 Device markers		
Operating temperature range	-29...93 °C		
Imprint	Neutral		

**Classifications**

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings

