


LM WO 18/34 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

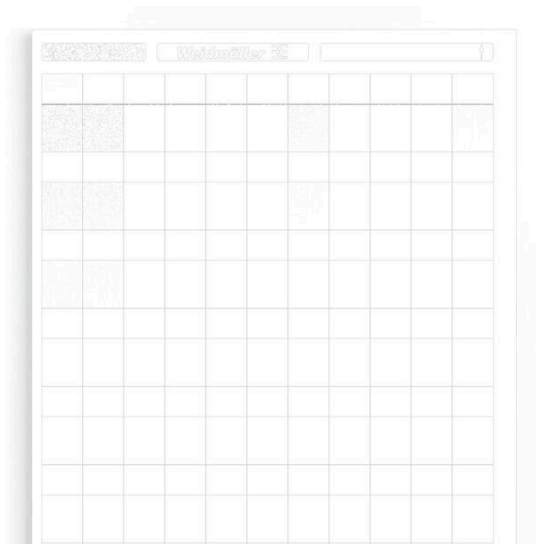

Similar to illustration



Self-adhesive polyester labels which are suitable for A4 office laser printer.

General ordering data

| | |
|------------|---|
| Version | LaserMark, Conductor and cable markers, 5 - 7 mm, 18 x 34 mm, white |
| Order No. | 1695711044 |
| Type | LM WO 18/34 WS |
| GTIN (EAN) | 4008 1909 2465 2 |
| Qty. | 10 items |

LM WO 18/34 WS

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Depth | 0.03 mm | Depth (inches) | 0.001 inch |
| Height | 18 mm | Height (inches) | 0.7087 inch |
| Width | 34 mm | Width (inches) | 1.3386 inch |
| Net weight | 10.2 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -40...150 °C |
|-----------------------------|--------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | |
|--|--|-------------|
| Adhesive | Acrylate | |
| Material colour according to resistance code | 9 | |
| Number per sheet | 88 | |
| Type of printing | neutral | |
| Version | Self-adhesive | |
| Width | 34 mm | |
| UL 94 flammability rating | V-0 | |
| Operating temperature range, max. | 150 °C | |
| Operating temperature range, min. | -40 °C | |
| Colour | white | |
| Halogen | No | |
| Basic material | Polyester film | |
| Printed characters | without | |
| Number of markers per packaging unit | 880 | |
| Number of markers per packaging unit | Form of supply | Label sheet |
| | Number of combinations per packaging unit | 10 |
| | Number of markers per combination | 88 |
| Size of labelling field | 17.8 x 13 mm | |
| Number of markers per combination | 1 Label sheet = 88 Conductor and cable markers | |
| Operating temperature range | -40...150 °C | |

Conductor and cable markers

| | | | |
|----------------------------------|------------------------|-------------------------------|--------------------|
| Halogen | No | Conductor cross-section, max. | 16 mm ² |
| Conductor cross-section, min. | 6 mm ² | Conductor O.D., max. | 7 mm |
| Conductor O.D., min. | 5 mm | Text field width | 13 mm |
| Text field height | 17.8 mm | Conductor O.D. | 5 - 7 mm |
| Cross-section for connected wire | 6 - 16 mm ² | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001530 | ETIM 9.0 | EC001530 |
| ETIM 10.0 | EC001530 | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 | | |

Drawings

