


**CBH 27/27 BK**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

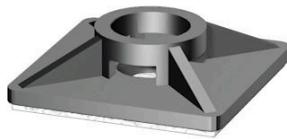

Similar to illustration

Fastening of cables or bundles with ties into electrical switchgears and cabinets.

**General ordering data**

Version	Cable ties, 27 x 27 mm, Plastic, 80 N
Order No.	<a href="#">1697960000</a>
Type	CBH 27/27 BK
GTIN (EAN)	4008 190883034
Qty.	3000 items

**Technical data**

**Approvals**

ROHS	Conform
------	---------

**Dimensions and weights**

Depth	2 mm	Depth (inches)	0.0787 inch
Height	27 mm	Height (inches)	1.063 inch
Width	27 mm	Width (inches)	1.063 inch
Length	2 mm	Length (inches)	0.0787 inch
Net weight	1.79 g		

**Temperatures**

Operating temperature range	-40...60 °C
-----------------------------	-------------

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Installation materials**

Max. cable tie width	4.8 mm	UV-resistant	Yes
For re-opening	No	Version	Self-adhesive
UL 94 flammability rating	V-2	Operating temperature range, max.	60 °C
Operating temperature range, min.	-40 °C	Halogen	No
Basic material	Plastic	Tensile strength	80 N
Tensile strength (Pound-force)	18 lbf	Diameter of fastening hole	4.8 mm

**Important note**

Product information	Number of bags in box (pieces): 30 Number of items in bag (pieces): 100 One delivery unit corresponds to one box quantity, and only multiples of the delivery unit can be ordered.
---------------------	--

**Classifications**

ETIM 8.0	EC000449	ETIM 9.0	EC000449
ETIM 10.0	EC000449	ECLASS 14.0	23-15-25-22
ECLASS 15.0	23-15-25-22		

**Drawings**

**Dimensional drawing**

