


**MARKO-C. 50X50X50 B/DR.**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

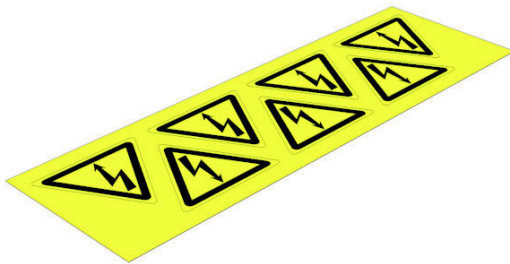

**General ordering data**

Version	Device markers, Device markers, 50 x 50 mm, yellow
Order No.	<a href="#">1700540001</a>
Type	MARKO-C. 50X50X50 B/DR.
GTIN (EAN)	4008190894306
Qty.	10 items

**MARKO-C. 50X50X50 B/DR.**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	0.05 mm	Depth (inches)	0.002 inch
Height	50 mm	Height (inches)	1.9685 inch
Width	50 mm	Width (inches)	1.9685 inch
Net weight	3.87 g		

**Temperatures**

Operating temperature range -29...80 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%

**General data**

Adhesive	Permanent acrylic copolymer		
Material colour according to resistance code	4		
Version	Self-adhesive		
Width	50 mm		
Operating temperature range, max.	80 °C		
Operating temperature range, min.	-29 °C		
Colour	yellow		
Basic material	Acrylic-coated fibre webbing		
Colour of printing	black		
Printed characters	Symbols		
Number of markers per packaging unit	70		
Number of markers per packaging unit	Form of supply	Label sheet	
	Number of combinations per packaging unit	10	
	Number of markers per combination	7	
Number of markers per combination	1 Label sheet = 7 Device markers		
Operating temperature range	-29...80 °C		
Imprint	Lightning flash in triangle		

**Classifications**

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

**MARKO-C. 50X50X50 B/DR.**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

**Drawings**

