

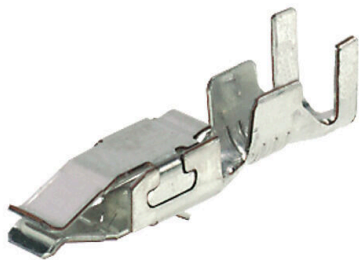
DFFC 0.2-0.35 ZRV1.5**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image

Similar to illustration

We offer a broad portfolio of mounting support for easy handling and supplementation of our products. From various tools to insulating sleeves and various screws, our components are matched to each other down to the last detail and thus facilitate assembly in compliance with the respective standards and protective regulations.

General ordering data

| | |
|------------|--|
| Version | Crimp contact (terminal), 0.35 mm ² |
| Order No. | 1705310000 |
| Type | DFFC 0.2-0.35 ZRV1.5 |
| GTIN (EAN) | 4008 190948573 |
| Qty. | 500 items |

DFFC 0.2-0.35 ZRV1.5

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 0.21 g

Temperatures

Ambient temperature -5 °C...40 °C Operating temperature 130 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

Material data

Basic material Plastic Surface finish tinned
 Colour silver

System specifications

Version for holding 0.2 ... 0.35 mm²

Additional technical data

Installation advice Direct mounting

Conductors for clamping (rated connection)

Stripping length 6 mm Type of connection Crimp contact
 Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. 0.35 mm² Wire connection cross section, finely stranded, max. 0.35 mm²

General

Installation advice Direct mounting Surface finish tinned

Rating data

Rated cross-section 0.35 mm² Volume resistance according to IEC 60947-7-x 1.83 mΩ
 Power loss in accordance with IEC 60947-7-x 0.56 W

Classifications

ETIM 8.0 EC000796 ETIM 9.0 EC000796
 ETIM 10.0 EC000796 ECLASS 14.0 27-44-02-04
 ECLASS 15.0 27-44-02-04