

WSM 10 D

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Similar to illustration

WSM small plates

- Completely rust-free and acid-resistant
- Embossed characters are still legible when painted
- Also available with custom printing, embossed on a carrier
- Contents of the WSM Service Box, 40 each of: 0-9, A-Ö, +, -, x, /, :, ,, ~, =, ü, Earth, Neutral. 200 steel cable ties (200 mm). 30 stainless steel carriers, 48 mm and 60 mm; 20 steel carriers, 84 mm, and 10 steel carriers, 108 mm and 288 mm

General ordering data

Version	Stainless steel markers, Conductor and cable markers, 5.5 x 9.9 mm, silver
Order No.	1712501643
Type	WSM 10 D
GTIN (EAN)	4008190947316
Qty.	200 items

WSM 10 D

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	0.3 mm	Depth (inches)	0.0118 inch
Height	5.5 mm	Height (inches)	0.2165 inch
Width	9.9 mm	Width (inches)	0.3898 inch
Net weight	0.13 g		

Temperatures

Operating temperature range 500 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

Orientation of print	horizontal		
Type of printing	Standard		
Width	9.9 mm		
Operating temperature range, max.	500 °C		
Colour	silver		
Halogen	No		
Basic material	Stainless steel 1.4404		
Printed characters	Upper-case letters		
Number of markers per packaging unit	Form of supply	Component part	
Number of markers per combination	1 Component part = Conductor and cable markers		
Operating temperature range	500 °C		
Imprint	D		

Conductor and cable markers

Halogen	No	Conductor cross-section, max.	500 mm ²
Conductor cross-section, min.	16 mm ²	Cross-section for connected wire	16 - 500 mm ²

Classifications

ETIM 8.0	EC001530	ETIM 9.0	EC001530
ETIM 10.0	EC001530	ECLASS 14.0	27-28-11-02
ECLASS 15.0	27-28-11-02		

WSM 10 D

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Stainless steel

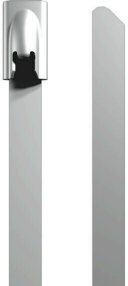

Weidmüller stainless steel Series contains a comprehensive assortment of stainless steel cable ties for extreme conditions such as high temperatures or severe chemical effects.

- stainless steel AISI 316,
- ideal for use outdoors,
- radiation- and corrosion-resistant,
- anti-magnetic,
- no serrations, so no damage to the insulation.

General ordering data

Type	SCT 4.6/838	Version
Order No.	1699940000	Cable ties, 4.6 x 838 mm, Stainless steel 1.4301, 445 N
GTIN (EAN)	4008190892388	
Qty.	100 ST	
Type	SCT 4.6/679	Version
Order No.	1699930000	Cable ties, 4.6 x 679 mm, Stainless steel 1.4301, 445 N
GTIN (EAN)	4008190892371	
Qty.	100 ST	
Type	SCT 4.6/520	Version
Order No.	1699920000	Cable ties, 4.6 x 520 mm, Stainless steel 1.4301, 445 N
GTIN (EAN)	4008190892364	
Qty.	100 ST	
Type	SCT 4.6/360 C	Version
Order No.	1699910000	Cable ties, 4.6 x 360 mm, Stainless steel 1.4301, 445 N
GTIN (EAN)	4008190892357	
Qty.	100 ST	
Type	SCT 4.6/266 C	Version
Order No.	1699900000	Cable ties, 4.6 x 266 mm, Stainless steel 1.4301, 445 N
GTIN (EAN)	4008190892340	
Qty.	100 ST	
Type	SCT 4.6/201 C	Version
Order No.	1699810000	Cable ties, 4.6 x 201 mm, Stainless steel 1.4301, 445 N
GTIN (EAN)	4008190892258	
Qty.	100 ST	
Type	SCT 4.6/127 C	Version
Order No.	1699800000	Cable ties, 4.6 x 127 mm, Stainless steel 1.4301, 445 N
GTIN (EAN)	4008190892241	
Qty.	100 ST	

WSM 10 D

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Holder



WSM is a complete marking system for cables, conductors, pipes and components - it offers permanent labelling in environments which no other marker is able to withstand. This product line consists of labelling plates, carriers and stainless steel cable ties – available individually or complete in the WSM Set and Service Box.

Advantages:

- Sturdy embossed characters for maximum legibility
- Resistant to heat, cold, corrosion, acids, chemicals, fire, etc.
- Individual and multi-character markings, can also be combined
- Quick installation
- Ideal for outdoor applications
- Easy attachment with cable ties

General ordering data

Type	WSMH 84MM	Version
Order No.	1774520000	Stainless steel markers, Conductor and cable markers, 14 - 79 mm,
GTIN (EAN)	4032248 149315	84 x 11 mm, silver
Qty.	50 ST	
Type	WSMH 60MM	Version
Order No.	1774510000	Stainless steel markers, Conductor and cable markers, 14 - 79 mm,
GTIN (EAN)	4032248 149308	60 x 11 mm, silver
Qty.	50 ST	
Type	WSMH 48MM	Version
Order No.	1774500000	Stainless steel markers, Conductor and cable markers, 14 - 79 mm,
GTIN (EAN)	4032248 149292	48 x 11 mm, silver
Qty.	50 ST	
Type	WSMH 288MM	Version
Order No.	1774490000	Stainless steel markers, Conductor and cable markers, 14 - 79 mm,
GTIN (EAN)	4032248 149285	288 x 11 mm, silver
Qty.	50 ST	
Type	WSMH 108MM	Version
Order No.	1774530000	Stainless steel markers, Conductor and cable markers, 14 - 79 mm,
GTIN (EAN)	4032248 149322	108 x 11 mm, silver
Qty.	50 ST	

Cable tie tools



WSM 10 D

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Accessories

www.weidmueller.com

General ordering data

Type	WSM TOOL AUTOMATIK	Version	
Order No.	1774470000	Stainless steel markers, Conductor and cable markers, 180 x 275	
GTIN (EAN)	4032248149261	mm, silver	
Qty.	1 ST		
Type	WSM TOOL MANUELL	Version	
Order No.	1774480000	Stainless steel markers, Conductor and cable markers, 210 x 220	
GTIN (EAN)	4032248149278	mm, silver	
Qty.	1 ST		