

ESG 7/20 SIRIUS MC NE WS


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

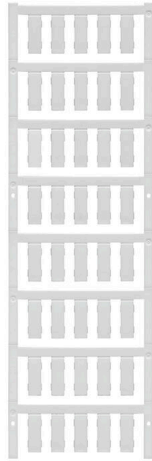

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | |
|------------|--|
| Version | ESG, Device markers x 20 mm, PA 66, Colour: white, pluggable |
| Order No. | 1736181044 |
| Type | ESG 7/20 SIRIUS MC NE WS |
| GTIN (EAN) | 4008190985950 |
| Qty. | 200 items |

ESG 7/20 SIRIUS MC NE WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 0.8 mm | Depth (inches) | 0.0315 inch |
| Height | 7 mm | Height (inches) | 0.2756 inch |
| Width | 20 mm | Width (inches) | 0.7874 inch |
| Net weight | 0.52 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -40...100 °C |
|-----------------------------|--------------|

Environmental Product Compliance

| | | |
|--------------------------|-----------------------------|------------------|
| RoHS Compliance Status | Compliant without exemption | |
| REACH SVHC | No SVHC above 0.1 wt% | |
| Product Carbon Footprint | Cradle to gate | 0.003 kg CO2 eq. |

General data

| | | |
|--|---|-----------|
| Material colour according to resistance code | 9 | |
| Number per sheet | 40 | |
| Version | pluggable | |
| Width | 20 mm | |
| UL 94 flammability rating | V-2 | |
| Operating temperature range, max. | 100 °C | |
| Operating temperature range, min. | -40 °C | |
| Colour | white | |
| Halogen | No | |
| Basic material | PA 66 | |
| Printed characters | without | |
| Number of markers per packaging unit | Form of supply | MultiCard |
| compatible printer | PRINTJET CONNECT , MCP BASIC 2 , MCP PLUS 2 | |
| Number of markers per combination | 1 MultiCard = Device markers | |
| Operating temperature range | -40...100 °C | |
| Application/manufacturer | Siemens Sirius 3R | |
| Number per roll | 40 | |

Device markers

| | |
|---------|----|
| Halogen | No |
|---------|----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001288 | ETIM 9.0 | EC001288 |
| ETIM 10.0 | EC001288 | ECLASS 14.0 | 27-28-11-04 |
| ECLASS 15.0 | 27-28-11-04 | | |

Drawings



ESG 7/20 SIRIUS MC NE WS

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Accessories



General ordering data

| | | | |
|------------|----------------------------|--|--|
| Type | SCHS3 K | Version | |
| Order No. | 1753480000 | Device markers, Accessories x 10 mm, PVC, Colour: black, Self-adhesive | |
| GTIN (EAN) | 4032248014347 | | |
| Qty. | 50 ST | | |

| | | | |
|------------|----------------------------|---|--|
| Type | SCHS4 K | Version | |
| Order No. | 1753460000 | Device markers, Accessories x 10 mm, PVC, Colour: grey, Self-adhesive | |
| GTIN (EAN) | 4032248014323 | | |
| Qty. | 50 ST | | |

WKM for inlay tags



The halogen-free, transparent pocket of the WKM offers outstanding protection against environmental influences. Thanks to firm fixation with cable ties, it is suitable for almost all wire cross-sections.

The pre-printed tags are simply inserted into the WKM holder and secured with a clip. WKM cable markers are the right solution for maximum efficiency in on-site marking. Your advantage when using WKM cables

- Paper and polyester labels can be printed individually with conventional office printers
- The robust design in combination with MultiCard ELS tags guarantees maximum protection against environmental influences

General ordering data

| | | | |
|------------|----------------------------|--|--|
| Type | WKM 8/20 | Version | |
| Order No. | 1753490000 | WKM, Conductor and cable markers, 7 - 115 mm, 20 x 8 mm, Wire and cable markers, Transparent | |
| GTIN (EAN) | 4032248010615 | | |
| Qty. | 50 ST | | |