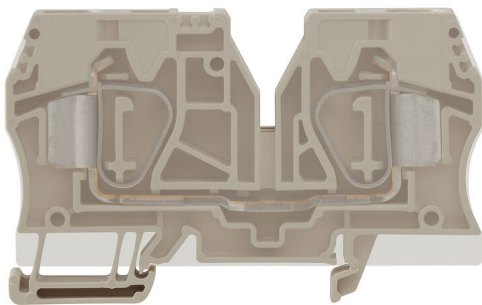


**ZEI 16****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)**Product image**

Our feed-in terminal blocks in combination with cross-connections offer the possibility of flexible potential distribution on terminal blocks with a different rated cross-section.

**General ordering data**

|            |                                                                                         |
|------------|-----------------------------------------------------------------------------------------|
| Version    | Supply terminal, Tension-clamp connection, 16 mm <sup>2</sup> , 500 V, 76 A, dark beige |
| Order No.  | <a href="#">1745350000</a>                                                              |
| Type       | ZEI 16                                                                                  |
| GTIN (EAN) | 4032248002689                                                                           |
| Qty.       | 20 items                                                                                |

## ZEI 16

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

## Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E60693

## Dimensions and weights

|                          |             |                |             |
|--------------------------|-------------|----------------|-------------|
| Depth                    | 50.5 mm     | Depth (inches) | 1.9882 inch |
| Depth including DIN rail | 51.5 mm     | Height         | 82.5 mm     |
| Height (inches)          | 3.248 inch  | Width          | 14.7 mm     |
| Width (inches)           | 0.5787 inch | Net weight     | 43.79 g     |

## Temperatures

|                                  |                |                                  |                |
|----------------------------------|----------------|----------------------------------|----------------|
| Storage temperature              | -25 °C...55 °C | Ambient temperature              | -50 °C...75 °C |
| Continuous operating temp., min. | -50 °C         | Continuous operating temp., max. | 120 °C         |

## Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

## Material data

|                           |       |        |            |
|---------------------------|-------|--------|------------|
| Basic material            | Wemid | Colour | dark beige |
| UL 94 flammability rating | V-0   |        |            |

## System specifications

|                                     |                                                                                         |                                   |       |
|-------------------------------------|-----------------------------------------------------------------------------------------|-----------------------------------|-------|
| Version                             | Supply terminal, Tension-clamp connection, for plug-in cross-connector, in closed state | End cover plate required          | No    |
| Number of potentials                | 1                                                                                       | Number of levels                  | 1     |
| Number of clamping points per level | 2                                                                                       | Levels cross-connected internally | No    |
| PE connection                       | No                                                                                      | Mounting rail                     | TS 35 |

## Additional technical data

|                     |         |                             |    |
|---------------------|---------|-----------------------------|----|
| Open sides          | closed  | Number of similar terminals | 1  |
| Installation advice | Busbar  | Explosion-tested version    | No |
| Type of mounting    | Snap-on |                             |    |

## CSA rating data

|                               |        |                       |                |
|-------------------------------|--------|-----------------------|----------------|
| Wire cross section max. (CSA) | 4 AWG  | Voltage size C (CSA)  | 600 V          |
| Current size C (CSA)          | 65 A   | Certificate No. (CSA) | 200039-1152892 |
| Voltage size B (CSA)          | 600 V  | Current size B (CSA)  | 65 A           |
| Voltage size D (CSA)          | 600 V  | Current size D (CSA)  | 5 A            |
| Wire cross section min. (CSA) | 14 AWG |                       |                |

## ZEI 16

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Technical data

## Conductors for clamping (additional connection)

Connection type, additional connection Tension-clamp connection

## Conductors for clamping (rated connection)

|                                                                                         |                          |                                                                                         |                     |
|-----------------------------------------------------------------------------------------|--------------------------|-----------------------------------------------------------------------------------------|---------------------|
| Gauge to IEC 60947-1                                                                    | A7                       | Wire connection cross section AWG, max.                                                 | AWG 4               |
| Connection direction                                                                    | top                      | Stripping length                                                                        | 18 mm               |
| Type of connection                                                                      | Tension-clamp connection | Number of connections                                                                   | 2                   |
| Clamping range, max.                                                                    | 25 mm <sup>2</sup>       | Clamping range, min.                                                                    | 1.5 mm <sup>2</sup> |
| Blade size                                                                              | 1.0 x 5.5 mm             | Wire connection cross section AWG, min.                                                 | AWG 14              |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, max. | 16 mm <sup>2</sup>       | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/4, min. | 1.5 mm <sup>2</sup> |
| Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, max. | 16 mm <sup>2</sup>       | Wire connection cross-section, finely stranded with wire-end ferrules DIN 46228/1, min. | 1.5 mm <sup>2</sup> |
| Wire connection cross section, finely stranded, max.                                    | 16 mm <sup>2</sup>       | Wire connection cross section, finely stranded, min.                                    | 1.5 mm <sup>2</sup> |
| Connection cross-section, stranded, max.                                                | 25 mm <sup>2</sup>       | Connection cross-section, stranded, min.                                                | 1.5 mm <sup>2</sup> |
| Wire connection cross-section, solid core, max.                                         | 16 mm <sup>2</sup>       | Wire connection cross-section, solid core, min.                                         | 1.5 mm <sup>2</sup> |

## General

|                                         |        |                     |               |
|-----------------------------------------|--------|---------------------|---------------|
| Wire connection cross section AWG, max. | AWG 4  | Installation advice | Busbar        |
| Wire connection cross section AWG, min. | AWG 14 | Standards           | IEC 60947-7-1 |
| Mounting rail                           | TS 35  |                     |               |

## Rating data

|                                              |                    |                                 |               |
|----------------------------------------------|--------------------|---------------------------------|---------------|
| Rated cross-section                          | 16 mm <sup>2</sup> | Rated voltage                   | 500 V         |
| Rated DC voltage                             | 500 V              | Nominal current                 | 76 A          |
| Current at maximum wires                     | 76 A               | Standards                       | IEC 60947-7-1 |
| Volume resistance according to IEC 60947-7-x | 0.42 mΩ            | Rated impulse withstand voltage | 8 kV          |
| Power loss in accordance with IEC 60947-7-x  | 2.43 W             | Pollution severity              | 3             |

 
## UL rating data

|                                            |        |                                            |        |
|--------------------------------------------|--------|--------------------------------------------|--------|
| Conductor size Factory wiring max. (cURus) | 4 AWG  | Certificate No. (cURus)                    | E60693 |
| Conductor size Field wiring min. (cURus)   | 14 AWG | Conductor size Factory wiring min. (cURus) | 14 AWG |
| Voltage size C (cURus)                     | 600 V  | Current size C (cURus)                     | 65 A   |
| Conductor size Field wiring max. (cURus)   | 4 AWG  |                                            |        |

## Classifications

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000897    | ETIM 9.0    | EC000897    |
| ETIM 10.0   | EC000897    | ECLASS 14.0 | 27-25-01-01 |
| ECLASS 15.0 | 27-25-01-01 |             |             |

Drawings



## Accessories

## Cross-connections



The distribution or multiplication of a potential to adjoining terminal blocks is realized via a cross-connection. Additional wiring effort can be easily avoided. Even if the poles are broken out, contact reliability in the terminal blocks is still ensured. Our portfolio offers pluggable and screwable cross-connection systems for modular terminal blocks.

## General ordering data

|            |                            |                                                                   |
|------------|----------------------------|-------------------------------------------------------------------|
| Type       | ZQV 2.5/2                  | Version                                                           |
| Order No.  | <a href="#">1608860000</a> | Z-series, Cross-connector, 24 A                                   |
| GTIN (EAN) | 4008190123680              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |
| Type       | ZQV 2.5/3                  | Version                                                           |
| Order No.  | <a href="#">1608870000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190061630              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |
| Type       | ZQV 2.5/4                  | Version                                                           |
| Order No.  | <a href="#">1608880000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190082208              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |
| Type       | ZQV 2.5/5                  | Version                                                           |
| Order No.  | <a href="#">1608890000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190065713              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 2.5/6                  | Version                                                           |
| Order No.  | <a href="#">1608900000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190149840              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 2.5/7                  | Version                                                           |
| Order No.  | <a href="#">1608910000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190159665              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 2.5/8                  | Version                                                           |
| Order No.  | <a href="#">1608920000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190061531              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 2.5/9                  | Version                                                           |
| Order No.  | <a href="#">1608930000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190117009              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 2.5/10                 | Version                                                           |
| Order No.  | <a href="#">1608940000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190099060              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 2.5/20                 | Version                                                           |
| Order No.  | <a href="#">1908960000</a> | Z-series, Cross-connector, For the terminals, Number of poles: 20 |
| GTIN (EAN) | 4032248535293              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |

## ZEI 16

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                                                                   |
|------------|----------------------------|-------------------------------------------------------------------|
| Type       | ZQV 2.5/50                 | Version                                                           |
| Order No.  | <a href="#">1697540000</a> | Accessories, Cross-connector, 24 A                                |
| GTIN (EAN) | 4008190883256              |                                                                   |
| Qty.       | 10 ST                      |                                                                   |
| Type       | ZQV 4/2 GE                 | Version                                                           |
| Order No.  | <a href="#">1608950000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263225              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |
| Type       | ZQV 4/3 GE                 | Version                                                           |
| Order No.  | <a href="#">1608960000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263232              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |
| Type       | ZQV 4/4 GE                 | Version                                                           |
| Order No.  | <a href="#">1608970000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263249              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |
| Type       | ZQV 4/5 GE                 | Version                                                           |
| Order No.  | <a href="#">1608980000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263256              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 4/6 GE                 | Version                                                           |
| Order No.  | <a href="#">1608990000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263263              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 4/7 GE                 | Version                                                           |
| Order No.  | <a href="#">1609000000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263270              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 4/8 GE                 | Version                                                           |
| Order No.  | <a href="#">1609010000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263287              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 4/9 GE                 | Version                                                           |
| Order No.  | <a href="#">1609020000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263294              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 4/10 GE                | Version                                                           |
| Order No.  | <a href="#">1609030000</a> | Accessories, Cross-connector, 32 A                                |
| GTIN (EAN) | 4008190263300              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 4/20 GE                | Version                                                           |
| Order No.  | <a href="#">1909010000</a> | Z-series, Cross-connector, For the terminals, Number of poles: 20 |
| GTIN (EAN) | 4032248535637              |                                                                   |
| Qty.       | 20 ST                      |                                                                   |
| Type       | ZQV 6/2 GE                 | Version                                                           |
| Order No.  | <a href="#">1627850000</a> | Accessories, Cross-connector, 41 A                                |
| GTIN (EAN) | 4008190200428              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |
| Type       | ZQV 6/3 GE                 | Version                                                           |
| Order No.  | <a href="#">1627860000</a> | Accessories, Cross-connector, 41 A                                |
| GTIN (EAN) | 4008190200435              |                                                                   |
| Qty.       | 60 ST                      |                                                                   |

## ZEI 16


**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Accessories

|            |                            |                                    |
|------------|----------------------------|------------------------------------|
| Type       | ZQV 6/4 GE                 | Version                            |
| Order No.  | <a href="#">1627870000</a> | Accessories, Cross-connector, 41 A |
| GTIN (EAN) | 4008190200442              |                                    |
| Qty.       | 60 ST                      |                                    |
| Type       | ZQV 6/24 GE                | Version                            |
| Order No.  | <a href="#">1908990000</a> | Accessories, Cross-connector, 41 A |
| GTIN (EAN) | 4032248535309              |                                    |
| Qty.       | 10 ST                      |                                    |
| Type       | ZQV 6/32 GE                | Version                            |
| Order No.  | <a href="#">1733640000</a> | Accessories, Cross-connector, 41 A |
| GTIN (EAN) | 4008190994334              |                                    |
| Qty.       | 10 ST                      |                                    |

## End bracket

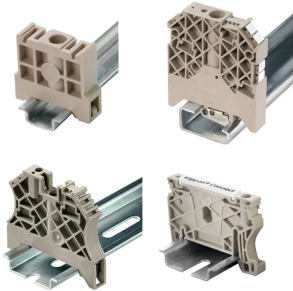

Weidmüller's range of products includes end brackets that guarantee a permanent, reliable mounting on the terminal rail and prevent sliding. Versions with and without screws are available. The end brackets include marking options, also for group markers, and also a test plug holder.

## General ordering data

|            |                            |                                                                  |
|------------|----------------------------|------------------------------------------------------------------|
| Type       | EW 35                      | Version                                                          |
| Order No.  | <a href="#">0383560000</a> | End bracket, beige, TS 35, V-2, Wemid, Width: 8.5 mm, 100 °C     |
| GTIN (EAN) | 4008190181314              |                                                                  |
| Qty.       | 50 ST                      |                                                                  |
| Type       | EW 35 GR 7032              | Version                                                          |
| Order No.  | <a href="#">0383530000</a> | End bracket, grey, TS 35, V-0, Wemid, Width: 9 mm, 120 °C        |
| GTIN (EAN) | 4008190027322              |                                                                  |
| Qty.       | 50 ST                      |                                                                  |
| Type       | EW 35/SCHA/M3              | Version                                                          |
| Order No.  | <a href="#">0258660000</a> | End bracket, beige, TS 35, V-2, Wemid, Width: 16.5 mm, 100 °C    |
| GTIN (EAN) | 4008190033477              |                                                                  |
| Qty.       | 20 ST                      |                                                                  |
| Type       | WEW 35/1                   | Version                                                          |
| Order No.  | <a href="#">1059000000</a> | End bracket, dark beige, TS 35, V-2, Wemid, Width: 12 mm, 100 °C |
| GTIN (EAN) | 4008190172282              |                                                                  |
| Qty.       | 50 ST                      |                                                                  |
| Type       | WEW 35/2                   | Version                                                          |
| Order No.  | <a href="#">1061200000</a> | End bracket, dark beige, TS 35, HB, Wemid, Width: 8 mm, 100 °C   |
| GTIN (EAN) | 4008190030230              |                                                                  |
| Qty.       | 50 ST                      |                                                                  |
| Type       | ZEW 35                     | Version                                                          |
| Order No.  | <a href="#">9540000000</a> | End bracket, dark beige, TS 35, V-2, Wemid, Width: 6 mm, 100 °C  |
| GTIN (EAN) | 4008190956264              |                                                                  |
| Qty.       | 20 ST                      |                                                                  |

## ZEI 16

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

|            |                            |                                                                 |
|------------|----------------------------|-----------------------------------------------------------------|
| Type       | ZEW 35/2                   | Version                                                         |
| Order No.  | <a href="#">8630740000</a> | End bracket, dark beige, TS 35, V-2, Wemid, Width: 8 mm, 100 °C |
| GTIN (EAN) | 4032248348916              |                                                                 |
| Qty.       | 20 ST                      |                                                                 |

## Testadapter and testsockets




Test adapters and test plugs are used for the electrical connection between terminal blocks and the test equipment. In this way, an electrical contact can be established in the wired state and measurements can be done easily.

## General ordering data

|            |                            |                                       |
|------------|----------------------------|---------------------------------------|
| Type       | PS 2.3 RT                  | Version                               |
| Order No.  | <a href="#">0180400000</a> | Test adapter (terminal), 230 V, 20 mA |
| GTIN (EAN) | 4008190060121              |                                       |
| Qty.       | 20 ST                      |                                       |

## Warning cover

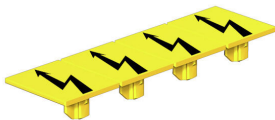

Warning covers with a flash symbol provide more safety for man and machine. They are used where external voltage must be indicated within the application.

## General ordering data

|            |                            |                 |
|------------|----------------------------|-----------------|
| Type       | ZAD 5/5                    | Version         |
| Order No.  | <a href="#">1745210000</a> | Z-series, Cover |
| GTIN (EAN) | 4008190071448              |                 |
| Qty.       | 20 ST                      |                 |

## Accessories

### STR transparent strips



#### General ordering data

|            |                            |                                                            |
|------------|----------------------------|------------------------------------------------------------|
| Type       | STR 7 F.SCHT 7             | Version                                                    |
| Order No.  | <a href="#">0515300000</a> | Terminal markers, Protective cap, 27 x 6.3 mm, Transparent |
| GTIN (EAN) | 4008190182175              |                                                            |
| Qty.       | 20 ST                      |                                                            |

### Blank



The Dekafix (DEK) marker is the universal marker for all conductor and plug-in connectors as well as for electronic sub-assemblies. The system is ideal for short number sequences and covers a wide range of ready-printed markers.

Strips for fast installation in only one work step. The printing is easy to read, rich in contrast and available in various widths.

- Large range of ready-to-use markers
  - Strips for fast installation
  - Terminal markers, suitable for all Weidmüller cable connectors
  - Available as blank MultiCard or with standard printing
- For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

#### General ordering data

|            |                            |                                                                    |
|------------|----------------------------|--------------------------------------------------------------------|
| Type       | DEK 5/5 MC NE WS           | Version                                                            |
| Order No.  | <a href="#">1609801044</a> | Dekafix, Terminal marker, 5 x 5 mm, Pitch in mm (P): 5.00          |
| GTIN (EAN) | 4008190397111              | Weidmueller, white                                                 |
| Qty.       | 1000 ST                    |                                                                    |
| Type       | WS 12/5 MC NE WS           | Version                                                            |
| Order No.  | <a href="#">1609860000</a> | WS, Terminal marker, 12 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4008190203481              | Allen-Bradley, white                                               |
| Qty.       | 720 ST                     |                                                                    |
| Type       | ZS 15/5 MC NE WS           | Version                                                            |
| Order No.  | <a href="#">1646630000</a> | ZS, Terminal marker, 15 x 5 mm, Pitch in mm (P): 5.00 Weidmueller, |
| GTIN (EAN) | 4008190401214              | Allen-Bradley, white                                               |
| Qty.       | 480 ST                     |                                                                    |

## ZEI 16

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## ZGB pivotable group tag holder

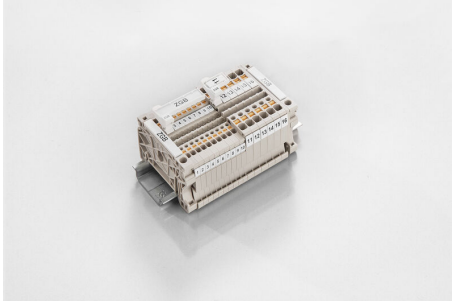

The ZGB 15 is a hinged group tag carrier. The tag carrier can hold the dekafix 5, WS 12/5 terminal markers or the inlay tag ESO 15.


The ZGB 30 is a hinged group tag carrier. The tag carrier can hold the dekafix 5, WS 12/5 terminal markers or the inlay tag ESO 7.

Inlay tags and protective strips can be found under "Accessories".

## General ordering data

|            |                            |                                                                     |
|------------|----------------------------|---------------------------------------------------------------------|
| Type       | ZGB 30                     | Version                                                             |
| Order No.  | <a href="#">1611930000</a> | Terminal markers, Terminal marker, 32 x 7 mm, Pitch in mm (P): 5.00 |
| GTIN (EAN) | 4008190002251              | Weidmueller, white                                                  |
| Qty.       | 20 ST                      |                                                                     |

## Marker holder

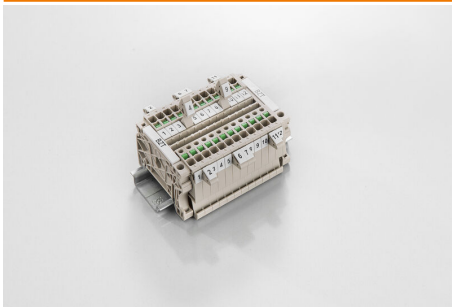

The marker holder offer the possibility of additional mounting of standard markers with a pitch of 5 or 5.1 mm. The angled holders can be optionally snapped together and could be mounted in all standard marking channels of the Klippon® Connect modular terminal blocks. Fitting marker types could be found under the respective accessories of the designation marking holder.

## General ordering data

|            |                            |                            |
|------------|----------------------------|----------------------------|
| Type       | BZT 1 WS 10/5              | Version                    |
| Order No.  | <a href="#">1805490000</a> | Accessories, Marker holder |
| GTIN (EAN) | 4032248270231              |                            |
| Qty.       | 100 ST                     |                            |

|            |                            |                            |
|------------|----------------------------|----------------------------|
| Type       | BZT 1 ZA WS 10/5           | Version                    |
| Order No.  | <a href="#">1805520000</a> | Accessories, Marker holder |
| GTIN (EAN) | 4032248270248              |                            |
| Qty.       | 100 ST                     |                            |

## ZEI 16

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## WS 12/5



## WS/ DEK

MultiMark terminal markers use an innovative composite material made from two components. The hard base contour of the marker snaps securely into the connector. The elastic surface finish makes the marker easy to mount. This specially punched material enables the strips to be stretched to accommodate the slight variations in spacing that tend to add up, especially with long terminal blocks. Another advantage: the excellent printability of the surface material guarantees durable and wear-resistant labelling. A print resolution of 300 dpi also produces a very legible script.

## Your benefits with MultiMark

- Firm hold and durable printing
- Continuous strips save installation time
- Easy mounting thanks to an innovative composite material
- Large label field for optimal legibility
- High flexibility thanks to manufacturer independence

## General ordering data

|            |                            |                                                    |
|------------|----------------------------|----------------------------------------------------|
| Type       | WS 12/5 MM WS              | Version                                            |
| Order No.  | <a href="#">2007190000</a> | WS, Terminal marker, 12 x 5 mm, Weidmueller, white |
| GTIN (EAN) | 4050118392036              |                                                    |
| Qty.       | 800 ST                     |                                                    |

## Slotted screwdriver



Slotted screwdriver with rounded blade SD DIN 5265, ISO 2380/2, output to DIN 5264, ISO 2380/1. ChromTop tip, SoftFinish grip

## General ordering data

|            |                            |                                                                                       |
|------------|----------------------------|---------------------------------------------------------------------------------------|
| Type       | SDS 1.0X5.5X150            | Version                                                                               |
| Order No.  | <a href="#">2749380000</a> | Screwdriver, Blade width (B): 5.5 mm, Blade length: 150 mm, Blade thickness (A): 1 mm |
| GTIN (EAN) | 4050118895605              |                                                                                       |
| Qty.       | 1 ST                       |                                                                                       |