

SCHT 5 S V0**Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26
D-32758 Detmold
Germanywww.weidmueller.com

The SchT 5 S group tag carriers are clipped directly onto the TS 32 mounting rail (G-rail) or the TS 35 mounting rail (top-hat rail). It is therefore possible to label the terminal strip irrespective of the terminal and the type of terminal. SchT 5 and SchT 5 S are fitted with ESO 5, STR 5 protective strips.

The SchT 7 is a hinged group tag carrier for inlay tags which enables easy access to the clamping screw. The SchT 7 is fitted with ESO 7, STR 7 protective strips or DEK 5.

Inlay tags and protective strips can be found under "Accessories".

General ordering data

Version	SCHT, Terminal marker, 44.5 x 9.5 mm, Pitch in mm (P): 5.00 beige
Order No.	1762370000
Type	SCHT 5 S V0
GTIN (EAN)	4032248043842
Qty.	20 items

SCHT 5 S V0

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Height	44.5 mm	Height (inches)	1.752 inch
Width	9.5 mm	Width (inches)	0.374 inch
Net weight	4.09 g		

Temperatures

Operating temperature range	-40...120 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Orientation of print	horizontal and vertical		
Type of printing	neutral		
Width	9.5 mm		
UL 94 flammability rating	V-0		
Operating temperature range, max.	120 °C		
Operating temperature range, min.	-40 °C		
Colour	beige		
Halogen	No		
Basic material	Polyamide 66		
Printed characters	without		
Number of markers per packaging unit	Form of supply	Component part	
Number of markers per combination	1 Component part = Terminal marker		
Operating temperature range	-40...120 °C		

Connector markers

Pitch in mm (P)	5.00 mm
-----------------	---------

Classifications

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-14-11-92
ECLASS 15.0	27-14-11-92		


SCHT 5 S V0

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

ESO insert tags

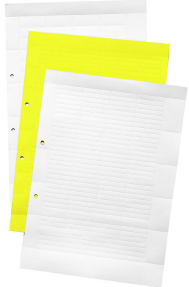

General ordering data

Type	ESO 5 S DIN A4 WS	Version	
Order No.	1631920000	Terminal markers, Insert markers, 40 x 7 mm, white	
GTIN (EAN)	4008190206673		
Qty.	10 ST		

STR transparent strips



General ordering data

Type	STR 5 S F.SCHT 5 S	Version	
Order No.	1631940000	Terminal markers, Protective cap, 40 x 7 mm, Transparent	
GTIN (EAN)	4008190206697		
Qty.	20 ST		

Blank



ELS MultiCard markers can be printed with a PrintJet, plotter or SMark printer. In particular, colour printing with PrintJet AVANCED allows the eye-catching identification marking of cables and terminal strips in many ways.

ELS 6/30 for use in the WKM 8/30 cable markers or in the EM8/30 group-tag carriers

ELS 7/40 for use in the SchT5S group-tag carriers

ELS 16/40 for use in the WKM 18/43 cable markers or the SchT5 group-tag carriers

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

SCHT 5 S V0**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Accessories****General ordering data**

Type	ELS 7/40 MC NE WS	Version
Order No.	1045640000	ELS, Insert markers, 0 - 0 mm, 40 x 7 mm, white
GTIN (EAN)	4032248836086	
Qty.	40 ST	
Type	ELS 7/40 MC NE GE	Version
Order No.	1045650000	ELS, Insert markers, 0 - 0 mm, 40 x 7 mm, yellow
GTIN (EAN)	4032248779635	
Qty.	40 ST	