

VP M32 K54**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Similar to illustration**

In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Version	VPK (blanking plug in plastic), Blanking plug, in closed state, M 32, 11 mm, IP65, Polyamid 6 (PA6 - GF30)
Order No.	1776940000
Type	VP M32 K54
GTIN (EAN)	4032248156382
Qty.	50 items

VP M32 K54

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Height	5 mm	Height (inches)	0.1968 inch
Length	7 mm	Length (inches)	0.2756 inch
Diameter	32 mm	Wall thickness, min.	0.5 mm
Wall thickness, max.	10 mm	Net weight	6.4 g

Temperatures

Operating temperature	-40 °C...100 °C
-----------------------	-----------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%


General information

Head diameter	37.00 mm	Protection degree with GWDR	IP65
UL 94 flammability rating	V-2	Operating temperature range, max.	100 °C
Operating temperature range, min.	-40 °C	Pitch of thread	1.5 mm
Halogen	No	Protection degree	IP54
Cable gland	metric	Basic material	Polyamid 6 (PA6 - GF30)
Diameter of sealing ring	32.00 mm	External thread	M 32
Length of thread	11 mm		

Classifications

ETIM 6.0	EC000451	ETIM 7.0	EC000451
ETIM 8.0	EC000451	ETIM 9.0	EC000451
ETIM 10.0	EC000451	ECLASS 9.0	27-14-44-25
ECLASS 9.1	27-14-44-33	ECLASS 10.0	27-14-44-25
ECLASS 11.0	27-14-44-25	ECLASS 12.0	27-14-08-05
ECLASS 13.0	27-14-08-05	ECLASS 14.0	27-14-08-05
ECLASS 15.0	27-14-08-05		

Drawings

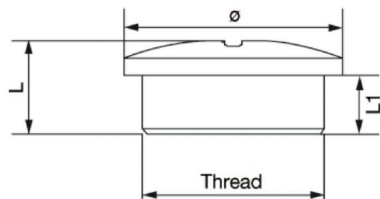

VP M32 K54

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Plastic lock nuts, grey



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	SKMU M32 - K GR	Version
Order No.	1772480000	SKMU PA (plastic locknut), Locknut, M 32, 7 mm, Polyamid 6 (PA6 -
GTIN (EAN)	4032248130221	GF30)
Qty.	100 ST	

Neoprene flat gasket - GWDR NP



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M32-NP	Version
Order No.	1736260000	GWDR NP (flat gasket - neoprene), Sealing ring, M 32, Neoprene
GTIN (EAN)	4008190956059	
Qty.	50 ST	

Polyethylene flat gasket - GWDR PO



In addition to cable glands for a wide range of applications, the product portfolio is rounded off by plugs, pressure compensation elements, adaptors and the corresponding accessories such as locknuts, sealing rings, flat washers and earthing rings.

General ordering data

Type	GWDR M32-PO	Version
Order No.	1777960000	GWDR PO (flat gasket - polyethylene), Sealing ring, M 32,
GTIN (EAN)	4032248158225	Polyethylene
Qty.	50 ST	