

HDC 32B TSLU 1M32G

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | |
|------------|---|
| Version | HDC enclosures, Installation size: 10, Protection degree: IP65, in plugged condition, Cable entry from side, Plug housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32 |
| Order No. | 1788420000 |
| Type | HDC 32B TSLU 1M32G |
| GTIN (EAN) | 4032248205950 |
| Qty. | 1 items |

HDC 32B TSLU 1M32G

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



| | |
|-------------------------|----------------------------|
| ROHS | Conform |
| UL File Number Search | UL Website |
| Certificate No. (cURus) | E92202 |

Dimensions and weights

| | | | |
|------------|----------|-----------------|-------------|
| Depth | 108.5 mm | Depth (inches) | 4.2716 inch |
| Height | 79 mm | Height (inches) | 3.1102 inch |
| Width | 82.5 mm | Width (inches) | 3.248 inch |
| Net weight | 345.84 g | | |

Temperatures

| | |
|-------------------|-------------------|
| Limit temperature | -40 °C ... 125 °C |
|-------------------|-------------------|

Environmental Product Compliance

| | | |
|------------------------|-----------------------------|-------------------------|
| RoHS Compliance Status | Compliant without exemption | |
| REACH SVHC | No SVHC above 0.1 wt% | |
| Chemical resistance | Substance | Acetone |
| | Chemical resistance | Conditionally resistant |
| | Substance | Drilling oil |
| | Chemical resistance | Resistant |
| | Substance | Diesel |
| | Chemical resistance | Resistant |
| | Substance | Ethyl alcohol |
| | Chemical resistance | Resistant |
| | Substance | Transmission oil |
| | Chemical resistance | Resistant |
| | Substance | Hydraulic oil |
| | Chemical resistance | Resistant |
| | Substance | Coolant |
| | Chemical resistance | Resistant |
| | Substance | Petroleum benzine |
| | Chemical resistance | Resistant |
| | Substance | Sweat |
| | Chemical resistance | Resistant |
| | Substance | Premium gasoline |
| | Chemical resistance | Conditionally resistant |
| Substance | Water | |
| Chemical resistance | Resistant | |
| Substance | UV | |
| Chemical resistance | Unstable | |
| Substance | Ozone | |
| Chemical resistance | Unstable | |

Dimensions

| | | | |
|----------------------|-----------|---------------------|---------|
| Cable entry | w. thread | Width housing C | 82.5 mm |
| Total length housing | 94 mm | Height of housing B | 79 mm |

HDC 32B TSLU 1M32G

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

General data

| | | | |
|----------------|----------------|-------------------|----------------------------|
| Surface finish | Powder coating | Protection degree | IP65, in plugged condition |
|----------------|----------------|-------------------|----------------------------|

Version

| | | | |
|------------------------------|-------------------------------------|--------------------------------|-------------------------------|
| Size of cable entries | M 32 | Top part/bottom part/lid | upper part |
| Cover | without cover | Tightening torque | 2 Nm |
| Number of cable entry on top | 0 | Number of cable entry sideways | 1 |
| Design of housing | Cable entry from side, Plug housing | Design of locking system | End-locking clamp, lower side |
| Design | Standard | Installation size | 10 |
| Cable entry | w. thread | Type | Plug |
| Clamp version | End-locking clamp | Sealing | no sealing |
| Internal thread | M 32 | Colour (RAL) | RAL 7035 |
| BG | 10 | Suitable for ModuPlug® | Yes |

Classifications


| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000437 | ETIM 9.0 | EC000437 |
| ETIM 10.0 | EC000437 | ECLASS 14.0 | 27-44-02-02 |
| ECLASS 15.0 | 27-44-02-02 | | |

HDC 32B TSLU 1M32G

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

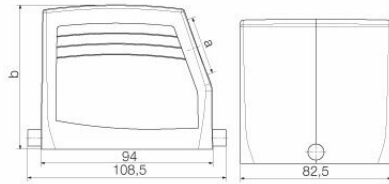

HDC 32B TSLU 1M32G

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

Base housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|--|
| Type | HDC 32B SLU 2M32G | Version |
| Order No. | 1788470000 | HDC enclosures, Installation size: 10, Protection degree: IP65, in plugged condition, Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32 |
| GTIN (EAN) | 4032248206001 | |
| Qty. | 1 ST | |
| Type | HDC 32B SDLU 2M32G | Version |
| Order No. | 1788490000 | HDC enclosures, Installation size: 10, Protection degree: IP65, in plugged condition, Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 32 |
| GTIN (EAN) | 4032248206025 | |
| Qty. | 1 ST | |
| Type | HDC 32B SDLU 1M32G | Version |
| Order No. | 1902650000 | HDC enclosures, Installation size: 10, Protection degree: IP65, in plugged condition, Base housing, End-locking clamp, lower side, Standard, with cover, Size of cable entries: M 32 |
| GTIN (EAN) | 4032248585656 | |
| Qty. | 1 ST | |
| Type | HDC 32B SLU 1M32G | Version |
| Order No. | 1902670000 | HDC enclosures, Installation size: 10, Protection degree: IP65, in plugged condition, Base housing, End-locking clamp, lower side, Standard, Size of cable entries: M 32 |
| GTIN (EAN) | 4032248585663 | |
| Qty. | 1 ST | |

HDC 32B TSLU 1M32G

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Bulkhead housing



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | HDC 32B ALU | Version |
| Order No. | 1219500000 | HDC enclosures, Installation size: 10, Protection degree: IP65, in |
| GTIN (EAN) | 4008190011826 | plugged condition, Bulkhead housing, End-locking clamp, lower side, |
| Qty. | 1 ST | Standard |
| Type | HDC 32B ADLU | Version |
| Order No. | 1219800000 | HDC enclosures, Installation size: 10, Protection degree: IP65, in |
| GTIN (EAN) | 4008190111090 | plugged condition, Bulkhead housing, End-locking clamp, lower side, |
| Qty. | 1 ST | Standard, with cover |

Coupling hood



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

General ordering data

| | | |
|------------|----------------------------|---|
| Type | HDC 32B KLU 1M32G | Version |
| Order No. | 1788500000 | HDC enclosures, Installation size: 10, Protection degree: IP65, in |
| GTIN (EAN) | 4032248206032 | plugged condition, Coupling housing, End-locking clamp, lower side, |
| Qty. | 1 ST | Standard, Size of cable entries: M 32 |