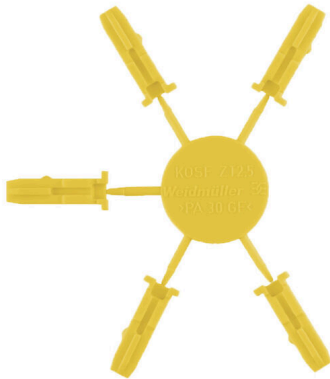


**KOSF ZT2.5****Weidmüller Interface GmbH & Co. KG**Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

**Product image**

The plugs for our WeiCoS-System are available for all different connection systems. The product range includes preassembled connectors from 1 to 10 poles and the possibility of an individual assembly. This ensures maximum flexibility for every application. The customized accessories increase the safety and protection against environmental influences.

**General ordering data**

Version	Z-series, Coding element, yellow, 2.9 mm
Order No.	<a href="#">1816150000</a>
Type	KOSF ZT2.5
GTIN (EAN)	4032248370726
Qty.	50 items

**KOSF ZT2.5**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Depth	11.25 mm	Depth (inches)	0.4429 inch
Height	4.4 mm	Height (inches)	0.1732 inch
Width	2.9 mm	Width (inches)	0.1142 inch
Net weight	0.2 g		

**Temperatures**

Storage temperature	-25 °C...55 °C	Ambient temperature	-50 °C...55 °C
Continuous operating temp., min.	-50 °C	Continuous operating temp., max.	100 °C

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Material data**

Basic material	PA 66 GF 30	Colour	yellow
UL 94 flammability rating	HB		

**System specifications**

Version Coding element

**Additional technical data**

Type of fixing	Plugged	Installation advice	Direct mounting
Explosion-tested version	No		

**General**

Installation advice Direct mounting

**Classifications**

ETIM 8.0	EC002848	ETIM 9.0	EC002848
ETIM 10.0	EC002848	ECLASS 14.0	27-25-03-90
ECLASS 15.0	27-25-03-90		

**Drawings**

