

SAIL-VSBD-180-15U(0,5)**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Weidmüller can supply valve plugs as connecting lines with M8/M12 plugs and one end without connector. The status of the valve plug is shown by an LED. The valve plugs have a protective circuit. The Weidmüller range includes valve plugs of type A, B and C to DIN and industry standards. Protection class IP 67 is fulfilled when screwed in. The outlet direction is also a decisive factor, therefore Weidmüller offers different versions.

General ordering data

Version	Sensor-actuator Cable, Number of poles: , 15 m, One end without connector - valve plug, LED: , Shielded: Yes
Order No.	1845161500
Type	SAIL-VSBD-180-15U(0,5)
GTIN (EAN)	4050118446708
Qty.	1 items

SAIL-VSBD-180-15U(0,5)

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

Dimensions and weights

Net weight 433.84 g

Environmental Product Compliance

RoHS Compliance Status Compliant
 REACH SVHC Lead 7439-92-1
 SCIP 4060c755-8d0b-4d43-bdb3-4ffabe9d7497

Technical specifications for cable

Cable length	15 m	Sheathing colour	black
Shielded	Yes	Sheath material	PUR
Irradiation crosslinked	No	Temperature range, stationary	-40...80 °C
Temperature range, moving	-25...80 °C	Outside diameter	4.6 mm ± 0.2 mm


General technical data

Version	One end without connector - valve plug	Temperature range of housing	-25...+80 °C
---------	--	------------------------------	--------------

Classifications

ETIM 8.0	EC001855	ETIM 9.0	EC001855
ETIM 10.0	EC001855	ECLASS 14.0	27-06-03-11
ECLASS 15.0	27-06-03-11		

Dimensioned drawing

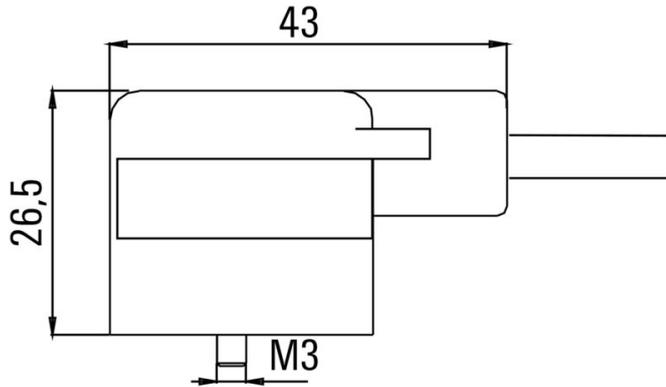

Wiring diagram

