

SAI-04L-VPFC-4A-M08L-PNP-10U03

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Similar to illustration

The new slim M8 line from Weidmüller. This range of products is characterised by the marking options at all connection positions. Even the 4-way distributor with 8-pole M12 has adequately large markers at all M8 connection positions. Furthermore, this distributor is shorter than many conventional M8 designs.

- Very narrow, short and flat M8 distributor.
- The range is supplied with 4 to 12 M8 connection positions, 3 or 4 poles.
- Hybrid variants of the M8 are also possible on request.
- The M8 line is equipped with transverse holes.

General ordering data

| | |
|------------|---|
| Version | Fixed cable version, M8, 30 V, , LED: Yes, LED initiator: Yes, Wiring type: PNP, 10 m |
| Order No. | 1849690000 |
| Type | SAI-04L-VPFC-4A-M08L-PNP-10U03 |
| GTIN (EAN) | 403224837668 1 |
| Qty. | 1 items |

SAI-04L-VPFC-4A-M08L-PNP-10U03

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E92202

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Depth | 18.2 mm | Depth (inches) | 0.7165 inch |
| Height | 92 mm | Height (inches) | 3.622 inch |
| Width | 24 mm | Width (inches) | 0.9449 inch |
| Net weight | 834 g | | |

Temperatures

Operating temperature -25 - 80°C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

Connection data

Sheathing stripping length 100 mm Distributor outlet Fixed cable version

Electrical data

| | | | |
|--------------------------------|------|---|-------|
| Rated voltage, min. | 10 V | Rated voltage, max. | 30 V |
| Test voltage | 1 kV | Max. current-carrying capacity per slot | 2 A |
| Total current | 6 A | Current per signal | 1 A |
| Electrical isolation available | No | Insulation resistance | 109 Ω |

General technical data

| | | | |
|-------------------------------------|-------|-----------------------------|--------|
| Protection degree | IP68 | Number of poles | 4 |
| Number of contact sockets | 4 | Connection thread | M8 |
| Pollution severity | 3 | Fire behaviour | V-0 |
| LED | Yes | LED initiator | Yes |
| LED colour for indicating operation | green | LED colour for I/O function | yellow |

Material data

| | | | |
|-------------------------|--------------------|--------------------------|-----------------------------|
| Material O-Ring | FKM | Housing main material | PBT |
| Material of distributor | Plastic | Housing colour | black (similar to RAL 9005) |
| Screw socket | Nickel-plated CuZn | Contact material | CuZn |
| Contact surface | Gold-plated | Contact carrier material | PBT (UL 94 V0) |

Technical data cable

| | | | |
|-----------------|--------|------------------|-------|
| Number of poles | 4 | Sheathing colour | black |
| O.D. | 7.4 mm | Shielded | No |

Creation date 26.02.2026 02:18:56 MEZ

Catalogue status / Drawings

SAI-04L-VPFC-4A-M08L-PNP-10U03

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

| | | | |
|-----------------------------|---------|-----------------------------------|---|
| Halogen | No | Bending radius, min., moving | 10 x cable diameter |
| Bending cycles | 1 mill. | Wire cross section (Print/Online) | 8 x 0.34 mm ² + 2 x 0.75 mm ² |
| Sheath material | PUR | Cable length | 10 m |
| Suitable for cable carriers | Yes | | |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC002585 | ETIM 9.0 | EC002585 |
| ETIM 10.0 | EC002585 | ECLASS 14.0 | 27-44-01-08 |
| ECLASS 15.0 | 27-44-01-08 | | |

SAI-04L-VPFC-4A-M08L-PNP-10U03


Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Drawings


www.weidmueller.com

Dimensioned drawing

Wiring

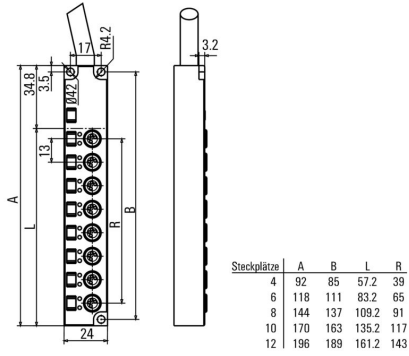

Pole scheme

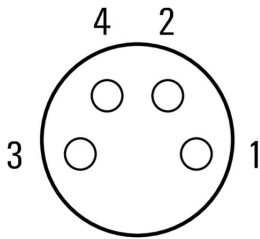

SAI-04L-VPFC-4A-M08L-PNP-10U03

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Screwty® cable gland tool with torque function



The ideal tool for any application
 Screwty® is the ideal, all-purpose tool for tightening all common sensor and actuator cables. Even difficult-to-reach round plugs are accessible using the Screwty®. A simple turning movement tightens and loosens the connectors without the need for excessive force. The Screwty® is a unique and global solution since it fits with most cables and plugs from other vendors (over 90 %). The Screwty® consists of a handle with a conventional 1/4" adapter. Thus it can be used for all sizes: for M12 and M8 round plug-in connectors, and for M12F and M8F customisable plugs and sockets, as well as for all M23 plugs and sockets.

General ordering data

| | | | |
|------------|----------------------------|---------|---|
| Type | SCREWTY SET -DM | Version | |
| Order No. | 1920000000 | | Cable gland tool for M8, M12 lines and connectors |
| GTIN (EAN) | 4032248436859 | | |
| Qty. | 1 ST | | |

M8



Protective caps protect unassigned plug-in stations against external influences.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | SAI-SK M8 | Version | |
| Order No. | 1802760000 | | Protected component assemblies, Protective cap |
| GTIN (EAN) | 4032248257379 | | |
| Qty. | 50 ST | | |

SAI-04L-VPFC-4A-M08L-PNP-10U03

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Blank



MultiFit is the Weidmüller marker system used for other makes of terminals. Similar to the Weidmüller Dekafix, the markers of the MultiFit family are available ready-for-use with standard printing.

We recommend to carry out a test with sample markers on the terminals used when using MultiFit for the first time.

- One marker, suitable for different makes of terminals.
- Ready-to-use markers with standard printing
- Blank markers for printing with the PrintJet CONNECT or Plotter
- Delivery of individually printed markers according to customer CAE data or specifications
- One marking system for all applications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | MFF 10/6 MC NE WS | Version | |
| Order No. | 1856780000 | | MultiFit, Terminal marker, 10 x 6 mm, Pitch in mm (P): 6.00 Festo, |
| GTIN (EAN) | 4032248400881 | | white |
| Qty. | 600 ST | | |