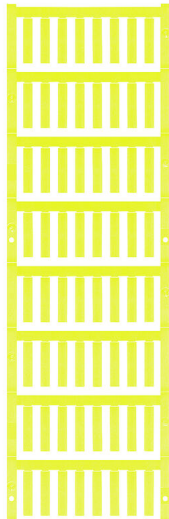


SF 3/21 MC NE GE V2**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

SlimFix are conductor and cable markers with a space-saving design. The markers can be fitted even after the conductor has been installed. They consist of halogen-free material and comply with flammability rating V0/V2. SlimFix is an acknowledged and accredited marker type for traffic engineering applications. The SF tool allows easy installation, even in case of small markers.

Advantages:

- Halogen-free material
- Flammability rating V0/V2
- Approved and accredited markers for traffic engineering applications, etc.
- Has to be fixed with cable ties if the conductor cross-section is larger than 16.0 mm²
- Markers in proven MultiCard format

General ordering data

Version	SlimFix, Conductor and cable markers, 3 - 3.7 mm, 21 x 4.6 mm, yellow
Order No.	1918890000
Type	SF 3/21 MC NE GE V2
GTIN (EAN)	4032248554270
Qty.	320 items

SF 3/21 MC NE GE V2

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	4.8 mm	Depth (inches)	0.189 inch
Height	21 mm	Height (inches)	0.8268 inch
Width	4.6 mm	Width (inches)	0.1811 inch
Net weight	0.41 g		

Temperatures

Operating temperature range	-40...100 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption		
REACH SVHC	No SVHC above 0.1 wt%		
Product Carbon Footprint	Cradle to gate	0.003 kg CO2 eq.	

General data

Type of printing	neutral		
Width	4.6 mm		
UL 94 flammability rating	V-2		
Operating temperature range, max.	100 °C		

Drawings

