

IE-PS-SCRJ-MM


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

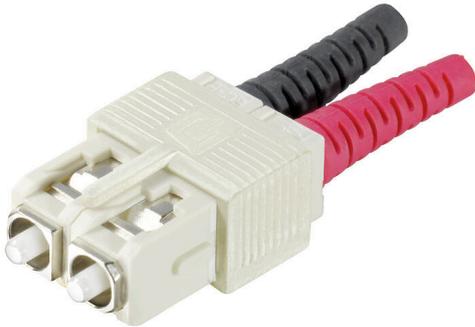

FO SC-RJ plug-in connectors according to IEC 61754-24
for wire outer diameters 2.6 to 3 mm

General ordering data

Version	FO connector, Plug SCRJ, multimode, IP20
Order No.	1962940000
Type	IE-PS-SCRJ-MM
GTIN (EAN)	4032248653997
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Last order date	2025-04-08T00:00:00+02:00

IE-PS-SCRJ-MM

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Net weight 8 g

Temperatures

Storage temperature Operating temperature -40 °C...70 °C
 Installation temperature

Environmental Product Compliance

RoHS Compliance Status Compliant with exemption
 RoHS Exemption (if applicable/known) 6c
 REACH SVHC Lead 7439-92-1
 SCIP 4f3aae94-c2bc-4010-b63b-5b114ba6bd55

General data

Description of article	Plug SCRJ, multimode	Colour	Miscellaneous
Protection degree	IP20	Plugging cycles	1000
Fibre type	Multimode	Insertion loss	≤ 0.4 dB
Connection 1	SCRJ	Connection 2	gluing, crimping, polishing
Return loss (attenuation)	≥ 30 dB	Ferrule material	Zirconia

General standards

Connector standard IEC 61754-24

Classifications

ETIM 8.0	EC001122	ETIM 9.0	EC001122
ETIM 10.0	EC001122	ECLASS 14.0	19-17-01-22
ECLASS 15.0	19-17-01-22		