

IE-PS-V04P-2SC-POF

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



PushPull plug-in connector set according to IEC
61076-3-106 ver.4 (IEC24702), plastic with SC insert

General ordering data

Version	FO connector, Version 4, SC-RJ POF, IP67
Order No.	1963380000
Type	IE-PS-V04P-2SC-POF
GTIN (EAN)	4032248651856
Qty.	10 items

IE-PS-V04P-2SC-POF

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	81.3 mm	Depth (inches)	3.2008 inch
Height	20.1 mm	Height (inches)	0.7913 inch
Width	20.2 mm	Width (inches)	0.7953 inch
Net weight	33.6 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

General data

Description of article	Version 4, SC-RJ POF	Colour	Miscellaneous
Housing main material	PA UL 94 V0	Sheath diameter, max.	10 mm
Sheath diameter, min.	5 mm	Protection degree	IP67
Plugging cycles	500	Fibre type	POF
Insertion loss	0.5 dB singlemode, 0.4 dB multimode, ≤ 1.0 dB POF	Connection 1	SCRJ
Connection 2	Rapid connection system: crimping, cutting	Housing material, insert	PA, Zinc diecast
Return loss (attenuation)	40 dB singlemode; 30 dB multimode		

General standards

Connector standard	IEC 61076-3-106 Var. 4, IEC 61754-24
--------------------	--------------------------------------

Classifications

ETIM 8.0	EC001122	ETIM 9.0	EC001122
ETIM 10.0	EC001122	ECLASS 14.0	19-17-01-22
ECLASS 15.0	19-17-01-22		


IE-PS-V04P-2SC-POF

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

Dimensioned drawing

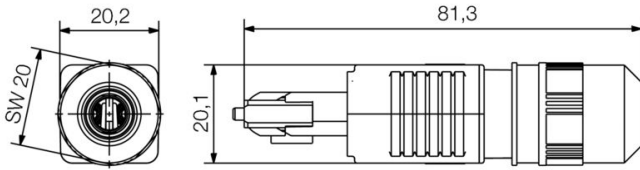

IE-PS-V04P-2SC-POF

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14




General ordering data

Type	IE-SCRJ-IP67-POF-100	Version	
Order No.	1278430000	FO connector, Replacement crimp barrel, IP67 with housing	
GTIN (EAN)	4050118069136		
Qty.	100 ST		

Crimp Sets

Crimp sets

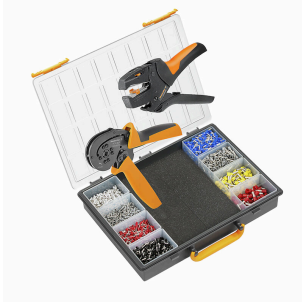

General ordering data

Type	TOOL SET IE-POF	Version	
Order No.	1208930000	Crimping tool: HTX-IE-POF, Stripping tool: Multi-Stripax IE-POF	
GTIN (EAN)	4032248990283		
Qty.	1 ST		

Dust caps

For protecting your devices against dust and dirt.



General ordering data

Type	IE-PP-V04P	Version	
Order No.	1963890000	Plug housing protective cap	
GTIN (EAN)	4032248646319		
Qty.	10 ST		

Accessories

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version	
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive	
GTIN (EAN)	4032248402731		
Qty.	200 ST		