

IE-PS-V04P-2SC-SM**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

PushPull plug-in connector set according to IEC
61076-3-106 ver.4 (IEC24702), plastic with SC insert

General ordering data

Version	FO connector, Variant 4, SC-Duplex single-mode, IP67
Order No.	1963400000
Type	IE-PS-V04P-2SC-SM
GTIN (EAN)	4032248651870
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2025-04-08T00:00:00+02:00

IE-PS-V04P-2SC-SM

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	81.3 mm	Depth (inches)	3.2008 inch
Height	20.1 mm	Height (inches)	0.7913 inch
Width	20.2 mm	Width (inches)	0.7953 inch
Net weight	3.85 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Description of article	Variant 4, SC-Duplex single-mode	Colour	Miscellaneous
Housing main material	PA UL 94 V0	Sheath diameter, max.	10 mm
Sheath diameter, min.	5 mm	Protection degree	IP67
Plugging cycles	500	Fibre type	Singlemode
Insertion loss	0.5 dB singlemode; 0.4 dB multimode; 1.5 dB POF	Connection 1	SCRJ
Connection 2	gluing, crimping, polishing	Housing material, insert	PA, Zinc diecast
Return loss (attenuation)	40 dB singlemode; 30 dB multimode		

General standards


Connector standard	IEC 61076-3-106 Var. 4, IEC 61754-24
--------------------	---

Classifications

ETIM 6.0	EC001122	ETIM 7.0	EC001122
ETIM 8.0	EC001122	ETIM 9.0	EC001122
ETIM 10.0	EC001122	ECLASS 9.0	19-17-01-22
ECLASS 9.1	19-17-01-22	ECLASS 10.0	19-17-01-22
ECLASS 11.0	19-17-01-22	ECLASS 12.0	19-17-01-22
ECLASS 13.0	19-17-01-22	ECLASS 14.0	19-17-01-22
ECLASS 15.0	19-17-01-22		

Drawings

 Dimensioned drawing



IE-PS-V04P-2SC-SM

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Dust caps




For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V04P	Version	
Order No.	1963890000	Plug housing protective cap	
GTIN (EAN)	4032248646319		
Qty.	10 ST		

Blank

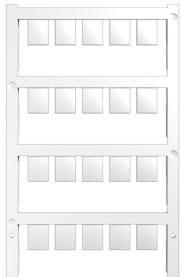

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version	
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive	
GTIN (EAN)	4032248402731		
Qty.	200 ST		