

IE-PS-V04P-2SC-SM-BP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



PushPull plug-in connector set according to IEC
61076-3-106 ver.4 (IEC24702), plastic with SC insert

General ordering data

Version	FO connector, Variant 4, SC-Duplex single-mode, with kink prevention, IP67
Order No.	1963410000
Type	IE-PS-V04P-2SC-SM-BP
GTIN (EAN)	4032248651887
Qty.	10 items
Delivery status	This article will no longer be available in the future.
Available until	2025-04-08T00:00:00+02:00

IE-PS-V04P-2SC-SM-BP

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS Conform

Dimensions and weights

Depth	129.8 mm	Depth (inches)	5.1102 inch
Height	20.1 mm	Height (inches)	0.7913 inch
Width	20.2 mm	Width (inches)	0.7953 inch
Net weight	53.4 g		

Temperatures

Storage temperature Operating temperature -40 °C...70 °C
 Installation temperature

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption
 REACH SVHC No SVHC above 0.1 wt%

General data

Description of article	Variant 4, SC-Duplex single-mode, with kink prevention	Colour	Miscellaneous
Housing main material	PA UL 94 V0	Sheath diameter, max.	10 mm
Sheath diameter, min.	5 mm	Protection degree	IP67
Plugging cycles	500	Fibre type	Singlemode
Insertion loss	0.5 dB singlemode; 0.4 dB multimode; 1.5 dB POF	Connection 1	SCRJ
Connection 2	gluing, crimping, polishing	Housing material, insert	PA, Zinc diecast
Return loss (attenuation)	40 dB singlemode; 30 dB multimode		

General standards

Connector standard IEC 61076-3-106 Var. 4, IEC 61754-24

Classifications

ETIM 8.0	EC001122	ETIM 9.0	EC001122
ETIM 10.0	EC001122	ECLASS 14.0	19-17-01-22
ECLASS 15.0	19-17-01-22		


IE-PS-V04P-2SC-SM-BP

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Dimensioned drawing

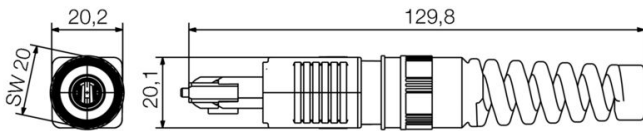

IE-PS-V04P-2SC-SM-BP

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Dust caps



For protecting your devices against dust and dirt.

General ordering data

Type	IE-PP-V04P	Version	
Order No.	1963890000	Plug housing protective cap	
GTIN (EAN)	4032248646319		
Qty.	10 ST		

Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version	
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive	
GTIN (EAN)	4032248402731		
Qty.	200 ST		