


## IE-BS-V04P-SCRJ2SC-SM-C

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

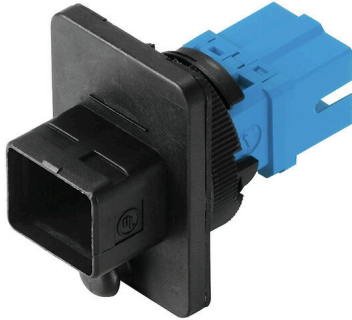

PushPull plug-in connector set according to IEC  
61076-3-106 ver.4 (IEC24702), plastic with SC insert

### General ordering data

Version	Flange FO, IP67, Version 4, coupling from SCRJ on 2*SC, Singlemode
Order No.	<a href="#">1963420000</a>
Type	IE-BS-V04P-SCRJ2SC-SM-C
GTIN (EAN)	4032248645510
Qty.	10 items

## IE-BS-V04P-SCRJ2SC-SM-C

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	48.3 mm	Depth (inches)	1.9016 inch
Height	38 mm	Height (inches)	1.4961 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	29.3 g		

### Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Description of article	Version 4, coupling from SCRJ on 2*SC	Colour	Miscellaneous
Housing main material	PA UL 94 V0	Protection degree	IP67
Plugging cycles	500	Fibre type	Singlemode
Insertion loss	≤ 0.5 dB	Connection 1	SC
Connection 2	SCRJ	Return loss (attenuation)	≥ 40 dB

### General standards

Connector standard	IEC 61076-3-106 Var. 4, IEC 61754-4, IEC 61754-24
--------------------	---------------------------------------------------

### Classifications

ETIM 8.0	EC000752	ETIM 9.0	EC000752
ETIM 10.0	EC000752	ECLASS 14.0	19-17-01-16
ECLASS 15.0	19-17-01-16		


IE-BS-V04P-SCRJ2SC-SM-C

Weidmüller Interface GmbH & Co. KG  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

Drawings

www.weidmueller.com

Installation cut-out

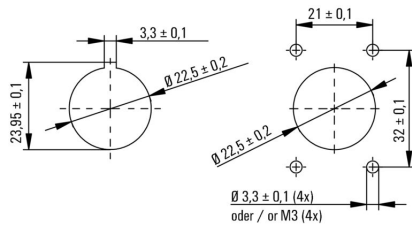

Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws