

IE-BS-V01M-SCRJ2SC-SM-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com



Bayonet plug-in connector sets according to IEC
61076-3-106 ver.1 (EtherNet/IP), RJ45 metal insert incl.
SC insert

General ordering data

Version	Flange FO, IP67, Version 1, coupling from SCRJ on 2*SC, Singlemode
Order No.	1963440000
Type	IE-BS-V01M-SCRJ2SC-SM-C
GTIN (EAN)	4032248645534
Qty.	10 items

IE-BS-V01M-SCRJ2SC-SM-C

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	36.6 mm	Depth (inches)	1.4409 inch
Height	32 mm	Height (inches)	1.2598 inch
Width	32 mm	Width (inches)	1.2598 inch
Net weight	62.1 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1, 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	c1a8d9e9-fd0c-4258-8c31-7317a7b4ce18

General data

Description of article	Version 1, coupling from SCRJ on 2*SC	Colour	Miscellaneous
Housing main material	Zinc diecast	Protection degree	IP67
Plugging cycles	500	Fibre type	Singlemode
Insertion loss	≤ 0.5 dB	Connection 1	SC
Connection 2	SCRJ	Return loss (attenuation)	≥ 40 dB

General standards

Connector standard	IEC 61076-3-106 Var. 1, IEC 61754-4, IEC 61754-24
--------------------	---

Classifications


ETIM 8.0	EC000752	ETIM 9.0	EC000752
ETIM 10.0	EC000752	ECLASS 14.0	19-17-01-16
ECLASS 15.0	19-17-01-16		

Installation cut-out



Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

Detailed drawing

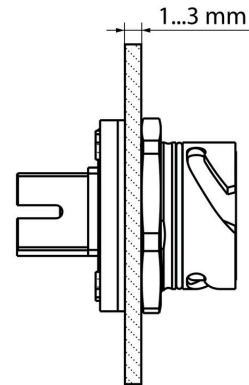

Wall thickness when using the central screw connection

IE-BS-V01M-SCRJ2SC-SM-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories

Dust caps



For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V01P	Version	
Order No.	1965700000	Flange-mounted housing, protective cap	
GTIN (EAN)	4032248653928		
Qty.	10 ST		