


IE-BH-V04P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

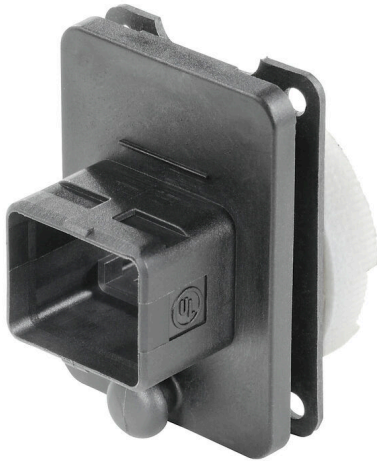

PushPull plug-in connector according to IEC
61076-3-106 ver.4 (IEC24702), plastic, empty housing

General ordering data

Version	Empty enclosure, Flange-mounted housing, Variant 4 to IEC 61076-3-106, IP67
Order No.	1963520000
Type	IE-BH-V04P
GTIN (EAN)	4032248645619
Qty.	10 items

IE-BH-V04P

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate no. (cULus) E316369

Dimensions and weights

Depth	28.7 mm	Depth (inches)	1.1299 inch
Height	38 mm	Height (inches)	1.4961 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	10 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Colour	Miscellaneous	Housing main material	PA UL 94 V0
Type of mounting	4 screws, Central nut	Protection degree	IP67
Plugging cycles	750		

General standards

Connector standard	IEC 61076-3-106 Var. 4	Certificate no. (cULus)	E316369
--------------------	------------------------	-------------------------	---------

Classifications

ETIM 8.0	EC001031	ETIM 9.0	EC001031
ETIM 10.0	EC001031	ECLASS 14.0	27-19-01-04
ECLASS 15.0	27-19-01-04		

Installation cut-out



Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Dust caps




For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V04P	Version	
Order No.	1963900000	Flange-mounted housing, protective cap	
GTIN (EAN)	4032248646326		
Qty.	10 ST		

RJ45

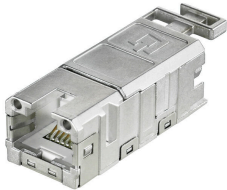

FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-BI-RJ45-FJ-B	Version	
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B	
GTIN (EAN)	4032248651894		
Qty.	10 ST		
Type	IE-BI-RJ45-FJ-P	Version	
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET	
GTIN (EAN)	4032248646159		
Qty.	10 ST		

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14



IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com


Accessories

General ordering data

Type	IE-BI-SCRJ2SC-SM-C	Version	
Order No.	1962870000	SC insert, Bulkhead insert SCRJ to 2 SC, singlemode	
GTIN (EAN)	4032248645060		
Qty.	10 ST		

LWL-LC


FO LC inserts for plug-in connectors ver.1 / 4 / 14

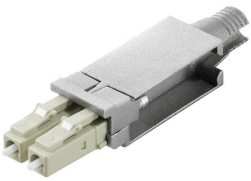

General ordering data

Type	IE-BI-LCD-SM-C	Version	
Order No.	1962880000	LC insert, Bulkhead insert LC duplex, singlemode	
GTIN (EAN)	4032248645077		
Qty.	10 ST		

RJ45

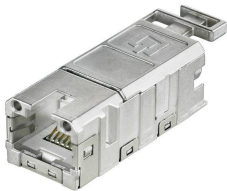

FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-BI-RJ45-FJ-A	Version	
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A	
GTIN (EAN)	4032248645053		
Qty.	10 ST		
Type	IE-BI-RJ45-C	Version	
Order No.	1962840000	RJ45 insert socket, Bulkhead inserts coupler	
GTIN (EAN)	4032248645046		
Qty.	10 ST		

IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

USB



FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-BI-USB-A	Version	
Order No.	1019570000	USB insert, Flange insert, type A	
GTIN (EAN)	4032248731602		
Qty.	1 ST		

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14




General ordering data

Type	IE-BI-SCRJ2SC-MM-C	Version	
Order No.	1964430000	SC insert, Bulkhead insert SCRJ to 2 SC, multimode	
GTIN (EAN)	4032248649044		
Qty.	10 ST		

LWL-LC

FO LC inserts for plug-in connectors ver.1 / 4 / 14

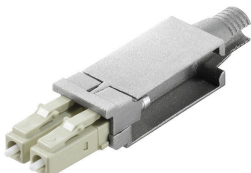

IE-BH-V04P

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com


Accessories

General ordering data

Type	IE-BH-LCD-MM-C	Version	
Order No.	1964420000	LC insert, Bulkhead insert LC duplex, multimode	
GTIN (EAN)	4032248649037		
Qty.	10 ST		

Hybrid


Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

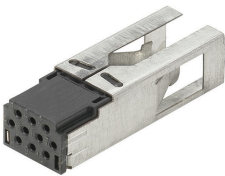

General ordering data

Type	IE-BH-HYB-10P	Version	
Order No.	1069010000	Flange insert, for flange insert, Hybrid	
GTIN (EAN)	4032248823970		
Qty.	10 ST		
Type	IE-BIC-HYB-P-0,5-300	Version	
Order No.	1096150000	Crimp contact, for flange insert, Hybrid	
GTIN (EAN)	4032248869114		
Qty.	300 ST		

Blank

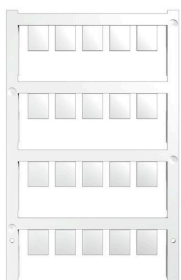

ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

General ordering data

Type	ESG 9/11 K MC NE WS	Version	
Order No.	1857440000	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive	
GTIN (EAN)	4032248402731		
Qty.	200 ST		