

IE-BH-V01M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Bayonet plug-in connectors according to IEC
61076-3-106 ver.1 (EtherNet/IP), metal, empty housing

General ordering data

Version	Empty enclosure, Flange-mounted housing, Variant 1 to IEC 61076-3-106, IP67
Order No.	1963540000
Type	IE-BH-V01M
GTIN (EAN)	4032248645633
Qty.	10 items

IE-BH-V01M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	23.5 mm	Depth (inches)	0.9252 inch
Height	32 mm	Height (inches)	1.2598 inch
Width	32 mm	Width (inches)	1.2598 inch
Net weight	46.6 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1, 6,6'-di-tert-butyl-2,2'-methylenedi-p-cresol 119-47-1
SCIP	c1a8d9e9-fd0c-4258-8c31-7317a7b4ce18

General data

Colour	Miscellaneous	Housing main material	Zinc diecast
Type of mounting	4 screws, Central nut	Protection degree	IP67
Plugging cycles	750		

General standards

Connector standard	IEC 61076-3-106 Var. 1
--------------------	------------------------

Classifications

ETIM 8.0	EC001031	ETIM 9.0	EC001031
ETIM 10.0	EC001031	ECLASS 14.0	27-19-01-04
ECLASS 15.0	27-19-01-04		

Installation cut-out



Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

Detailed drawing



Wall thickness when using the central screw connection

IE-BH-V01M

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

RJ45

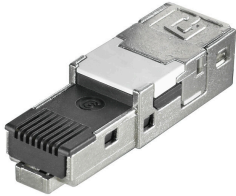

RJ45 inserts for plug-in connectors ver.1 / 4 / 5 / 14,
HDC and junction boxes IE-OM...; IE-OP...; IE-CC...

General ordering data

Type	IE-BI-RJ45-C	Version
Order No.	1962840000	RJ45 insert socket, Bulkhead inserts coupler
GTIN (EAN)	4032248645046	
Qty.	10 ST	
Type	IE-BI-RJ45-FJ-A	Version
Order No.	1962850000	RJ45 insert socket, Connector for base, TIA-568A
GTIN (EAN)	4032248645053	
Qty.	10 ST	
Type	IE-BI-RJ45-FJ-B	Version
Order No.	1963840000	RJ45 insert socket, Connector for base, TIA-568B
GTIN (EAN)	4032248651894	
Qty.	10 ST	
Type	IE-BI-RJ45-FJ-P	Version
Order No.	1963830000	RJ45 insert socket, Connector for base, PROFINET
GTIN (EAN)	4032248646159	
Qty.	10 ST	

LWL-SC

FO SC inserts for plug-in connectors ver.1 / 4 / 14



General ordering data

Type	IE-BI-SCRJ2SC-MM-C	Version
Order No.	1964430000	SC insert, Bulkhead insert SCRJ to 2 SC, multimode
GTIN (EAN)	4032248649044	
Qty.	10 ST	
Type	IE-BI-SCRJ2SC-SM-C	Version
Order No.	1962870000	SC insert, Bulkhead insert SCRJ to 2 SC, singlemode
GTIN (EAN)	4032248645060	
Qty.	10 ST	

IE-BH-V01M


Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

Accessories

www.weidmueller.com

LWL-LC

FO LC inserts for plug-in connectors ver.1 / 4 / 14

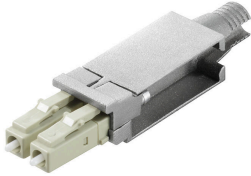

General ordering data

Type	IE-BH-LCD-MM-C	Version	
Order No.	1964420000	LC insert, Bulkhead insert LC duplex, multimode	
GTIN (EAN)	4032248649037		
Qty.	10 ST		
Type	IE-BH-LCD-SM-C	Version	
Order No.	1962880000	LC insert, Bulkhead insert LC duplex, singlemode	
GTIN (EAN)	4032248645077		
Qty.	10 ST		

USB




FrontCom® Vario integrates multiple functions in only one single frame. The system is easy to install and you can select from a wide range of data, signal and power modules. In addition to being extremely compact, FrontCom® Vario offers a number of unique product features that will make your project planning and work activities secure, fast and future-proof. Furthermore, the FrontCom® Vario system has an attractive housing design that, by the way, offers highest impact-resistance and fully meets the requirements of IP 65 protection class.

General ordering data

Type	IE-BI-USB-A	Version	
Order No.	1019570000	USB insert, Flange insert, type A	
GTIN (EAN)	4032248731602		
Qty.	1 ST		

Hybrid

Hybrid, 10-pole. Inserts for plug-in connectors Variant 14

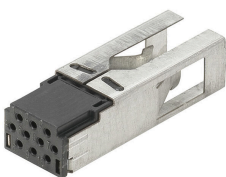

IE-BH-V01M

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

General ordering data

Type	IE-BH-HYB-10P	Version
Order No.	1069010000	Flange insert, for flange insert, Hybrid
GTIN (EAN)	4032248823970	
Qty.	10 ST	
Type	IE-BIC-HYB-P-0,5-300	Version
Order No.	1096150000	Crimp contact, for flange insert, Hybrid
GTIN (EAN)	4032248869114	
Qty.	300 ST	

Dust caps



For protecting your devices against dust and dirt.

General ordering data

Type	IE-BP-V01P	Version
Order No.	1965700000	Flange-mounted housing, protective cap
GTIN (EAN)	4032248653928	
Qty.	10 ST	