

**HDC 04A DODL 1LB**
**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

**General ordering data**

|            |  |
|------------|--|
| Version    | HDC enclosures, Installation size: 1, Protection degree: IP65, in plugged condition, Cover for upper part of housing, Side-locking clamp on lower side, Standard |
| Order No.  | <a href="#">1963690000</a>   |
| Type       | HDC 04A DODL 1LB   |
| GTIN (EAN) | 4032248645961  |
| Qty.       | 1 items  |

**HDC 04A DODL 1LB**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

Approvals



ROHS Conform

**Dimensions and weights**

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Height     | 25 mm   | Height (inches) | 0.9842 inch |
| Width      | 36.5 mm | Width (inches)  | 1.437 inch  |
| Net weight | 30 g    |                 |             |

**Temperatures**

Limit temperature -40 °C ... 125 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

|                     |                     |                         |
|---------------------|---------------------|-------------------------|
| Chemical resistance | Substance           | Acetone                 |
|                     | Chemical resistance | Conditionally resistant |
|                     | Substance           | Drilling oil            |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Diesel                  |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Ethyl alcohol           |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Transmission oil        |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Hydraulic oil           |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Coolant                 |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Petroleum benzine       |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Sweat                   |
|                     | Chemical resistance | Resistant               |
|                     | Substance           | Premium gasoline        |
|                     | Chemical resistance | Conditionally resistant |
| Substance           | Water               |                         |
| Chemical resistance | Resistant           |                         |
| Substance           | UV                  |                         |
| Chemical resistance | Unstable            |                         |
| Substance           | Ozone               |                         |
| Chemical resistance | Unstable            |                         |

**Dimensions**

|                      |           |                     |         |
|----------------------|-----------|---------------------|---------|
| Cable entry          | with male | Width housing C     | 26.8 mm |
| Total length housing | 31 mm     | Height of housing B | 18 mm   |

**General data**

Surface finish Powder coating Protection degree IP65, in plugged condition

**HDC 04A DODL 1LB**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Technical data**

[www.weidmueller.com](http://www.weidmueller.com)

**Version**

|                          |                                 |                                |                                  |
|--------------------------|---------------------------------|--------------------------------|----------------------------------|
| Top part/bottom part/lid | Cover                           | Cover                          | with cover                       |
| Tightening torque        | 0.5 Nm                          | Number of cable entry sideways | 0                                |
| Design of housing        | Cover for upper part of housing | Design of locking system       | Side-locking clamp on lower side |
| Design                   | Standard                        | Installation size              | 1                                |
| Cable entry              | with male                       | Clamp version                  | Side-locking clamp               |
| Sealing                  | no sealing                      | Colour (RAL)                   | RAL 7035                         |
| BG                       | 1                               | Suitable for ModuPlug®         | No                               |

**Classifications**


|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000437    | ETIM 9.0    | EC000437    |
| ETIM 10.0   | EC000437    | ECLASS 14.0 | 27-44-02-02 |
| ECLASS 15.0 | 27-44-02-02 |             |             |

**HDC 04A DODL 1LB**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

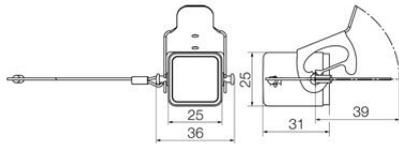

## HDC 04A DODL 1LB

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

## Plug enclosure, cable entry at top



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## General ordering data

|            |                            |   |  |
|------------|----------------------------|---|--|
| Type       | HDC 04A TOLU 1M16G         | Version   |  |
| Order No.  | <a href="#">1206090000</a> | HDC enclosures, Installation size: 1, Protection degree: IP65, in plugged condition, Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 16  |  |
| GTIN (EAN) | 4050118027587              |   |  |
| Qty.       | 1 ST                       |   |  |
| Type       | HDC 04A TOLU 1M20G         | Version   |  |
| Order No.  | <a href="#">1788820000</a> | HDC enclosures, Installation size: 1, Protection degree: IP65, in plugged condition, Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 20  |  |
| GTIN (EAN) | 4032248206360              |   |  |
| Qty.       | 1 ST                       |   |  |
| Type       | HDC 04A TOLU 1PG11G        | Version   |  |
| Order No.  | <a href="#">1652470000</a> | HDC enclosures, Installation size: 1, Protection degree: IP65, in plugged condition, Cable entry from top, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 11 |  |
| GTIN (EAN) | 4008190402549              |   |  |
| Qty.       | 1 ST                       |   |  |

## Plug enclosure, cable entry sideways



The special die-cast alloy and the multi-layered surface sealing provide complete protection for the HDC housings.

The cleverly designed interlock system is manufactured from stainless steel. This guarantees a long lifespan with high resistance to corrosion and impact.

The housing interlock system provides integrated safety. Our unique, patented spring system provides the housing interlock with a secure grip and prevents accidental opening.

The laser marking allows for easy and quick identification. Each housing is permanently labelled with a laser marking so that each product can be quickly designated and positioned.

Weidmüller RockStar® IP 65 / NEMA Type 4X housings - your first choice for industrial housings with IP 65 protection.

## HDC 04A DODL 1LB

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

## Accessories

[www.weidmueller.com](http://www.weidmueller.com)

### General ordering data

|            |                            |  |  |
|------------|----------------------------|--|--|
| Type       | HDC 04A TWLU 1PG11G        | Version  |  |
| Order No.  | <a href="#">1652480000</a> | HDC enclosures, Installation size: 1, Protection degree: IP65, in plugged condition, Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: PG 11 |  |
| GTIN (EAN) | 4008190402556              |  |  |
| Qty.       | 1 ST                       |  |  |
| Type       | HDC 04A TWLU 1M20G         | Version  |  |
| Order No.  | <a href="#">1788810000</a> | HDC enclosures, Installation size: 1, Protection degree: IP65, in plugged condition, Cable entry from side, Plug housing, Side-locking clamp on lower side, Standard, Size of cable entries: M 20  |  |
| GTIN (EAN) | 4032248206353              |  |  |
| Qty.       | 1 ST                       |  |  |