


**IE-BI-SCRJ2SC-MM-C**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

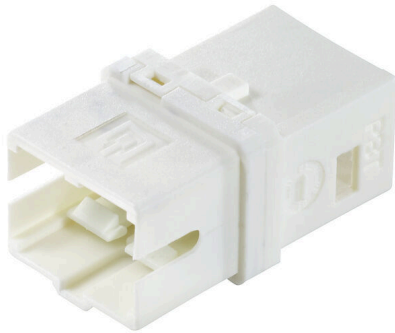

FO SC inserts for plug-in connectors ver.1 / 4 / 14

**General ordering data**

Version	SC insert, Bulkhead insert SCRJ to 2 SC, multi-mode
Order No.	<a href="#">1964430000</a>
Type	IE-BI-SCRJ2SC-MM-C
GTIN (EAN)	4032248649044
Qty.	10 items

## IE-BI-SCRJ2SC-MM-C

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

## Approvals

ROHS	Conform
------	---------

## Dimensions and weights

Depth	34 mm	Depth (inches)	1.3386 inch
Height	13.2 mm	Height (inches)	0.5197 inch
Width	15.6 mm	Width (inches)	0.6142 inch
Net weight	1.1 g		

## Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

## Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	d1193a9e-dc7c-484a-ba48-176711eb392b

## General data

Description of article	Bulkhead insert SCRJ to 2 SC, multimode	Colour	Miscellaneous
Housing main material	PA	Protection degree	IP67 with housing
Plugging cycles	1000	Composition	Connector and flange insert for variant 1, 4 and 14 housings
Fibre type	Multimode, POF	Insertion loss	≤ 0.4 dB
Connection 1	SC	Connection 2	SCRJ
Return loss (attenuation)	≥ 30 dB		

## General standards

Connector standard	IEC 61754-4, IEC 61754-24
--------------------	---------------------------

## Classifications

ETIM 8.0	EC000752	ETIM 9.0	EC000752
ETIM 10.0	EC000752	ECLASS 14.0	19-17-01-16
ECLASS 15.0	19-17-01-16		

**IE-BI-SCRJ2SC-MM-C**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

**Dimensioned drawing**

