


IE-BI-SCRJ2SC-MM-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

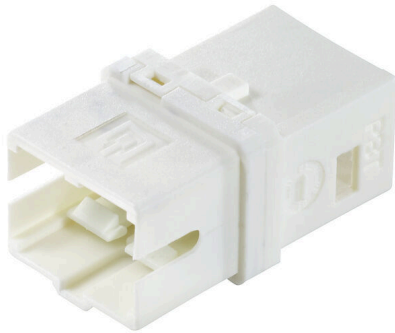

FO SC inserts for plug-in connectors ver.1 / 4 / 14

General ordering data

Version	SC insert, Bulkhead insert SCRJ to 2 SC, multi-mode
Order No.	1964430000
Type	IE-BI-SCRJ2SC-MM-C
GTIN (EAN)	4032248649044
Qty.	10 items

IE-BI-SCRJ2SC-MM-C

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	34 mm	Depth (inches)	1.3386 inch
Height	13.2 mm	Height (inches)	0.5197 inch
Width	15.6 mm	Width (inches)	0.6142 inch
Net weight	1.1 g		

Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1

General data

Description of article	Bulkhead insert SCRJ to 2 SC, multimode	Colour	Miscellaneous
Housing main material	PA	Protection degree	IP67 with housing
Plugging cycles	1000	Composition	Connector and flange insert for variant 1, 4 and 14 housings
Fibre type	Multimode, POF	Insertion loss	≤ 0.4 dB
Connection 1	SC	Connection 2	SCRJ
Return loss (attenuation)	≥ 30 dB		

General standards

Connector standard	IEC 61754-4, IEC 61754-24
--------------------	---------------------------

Classifications

ETIM 8.0	EC000752	ETIM 9.0	EC000752
ETIM 10.0	EC000752	ECLASS 14.0	19-17-01-16
ECLASS 15.0	19-17-01-16		

IE-BI-SCRJ2SC-MM-C

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

Drawings

www.weidmueller.com

Dimensioned drawing

