


## IE-BS-V04P-SCRJ2SC-MM-C

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

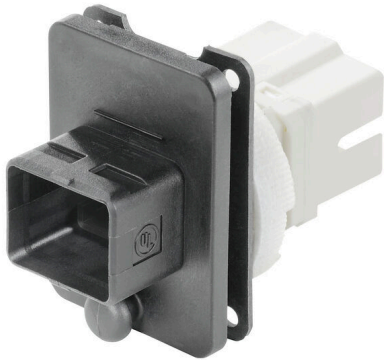

PushPull plug-in connector set according to IEC  
61076-3-106 ver.4 (IEC24702), plastic with SC insert

### General ordering data

Version	Flange FO, IP67, Version 4, coupling from SCRJ on 2*SC, Multimode, POF
Order No.	<a href="#">1964470000</a>
Type	IE-BS-V04P-SCRJ2SC-MM-C
GTIN (EAN)	4032248649075
Qty.	10 items

## IE-BS-V04P-SCRJ2SC-MM-C

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	48.3 mm	Depth (inches)	1.9016 inch
Height	38 mm	Height (inches)	1.4961 inch
Width	27 mm	Width (inches)	1.063 inch
Net weight	3.25 g		

### Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Description of article	Version 4, coupling from SCRJ on 2*SC	Colour	Miscellaneous
Housing main material	PA UL 94 V0	Protection degree	IP67
Plugging cycles	500	Fibre type	Multimode, POF
Insertion loss	≤ 0.4 dB	Connection 1	SC
Connection 2	SCRJ	Return loss (attenuation)	≥ 30 dB

### General standards

Connector standard	IEC 61076-3-106 Var. 4, IEC 61754-4, IEC 61754-24
--------------------	---

### Classifications

ETIM 8.0	EC000752	ETIM 9.0	EC000752
ETIM 10.0	EC000752	ECLASS 14.0	19-17-01-16
ECLASS 15.0	19-17-01-16		

Installation cut-out



Mounting cut-out: 1. With central screw connection / 2. For mounting with four M3 screws

## IE-BS-V04P-SCRJ2SC-MM-C

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

## Dust caps



For protecting your devices against dust and dirt.

## General ordering data

Type	IE-BP-V04P	Version	
Order No.	<a href="#">1963900000</a>	Flange-mounted housing, protective cap	
GTIN (EAN)	4032248646326		
Qty.	10 ST		

## Blank



ESG is the tried-and-tested marker in MultiCard format for use on many well-known electrical devices. The result is high-quality device marking with a high-contrast appearance.

Various types are available for devices from manufacturers like Siemens, ABB, Beckhoff etc.

Advantages at a glance:

- Tags for universal usage, self-adhesive or clip-on tags, depending on type
- For aligned equipment, e.g. circuit breakers, we supply ESG markers for clipping onto tag rails
- Individual laser-quality printing according to specifications

For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

## General ordering data

Type	ESG 9/11 K MC NE WS	Version	
Order No.	<a href="#">1857440000</a>	ESG, Device markers x 11 mm, PA 66, Colour: white, Self-adhesive	
GTIN (EAN)	4032248402731		
Qty.	200 ST		