


**IE-OM-V04P-K11-1S**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

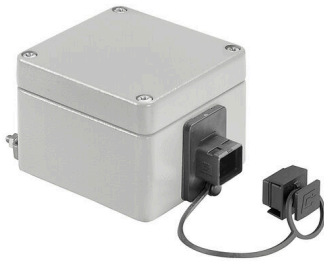

Similar to illustration

Junction box, design for PushPull plug-in connectors ver.4  
according to IEC 61076-3-106, metal

**General ordering data**

Version	Junction box, IP67, Variant 4, 1 port, straight
Order No.	<a href="#">1966220000</a>
Type	IE-OM-V04P-K11-1S
GTIN (EAN)	4032248658411
Qty.	1 items

## IE-OM-V04P-K11-1S

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	57 mm	Depth (inches)	2.2441 inch
Width	75 mm	Width (inches)	2.9527 inch
Length	140 mm	Length (inches)	5.5118 inch
Net weight	419 g		

### Temperatures

Storage temperature	Operating temperature	-40 °C...70 °C
Installation temperature		

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%
SCIP	4f3aae94-c2bc-4010-b63b-5b114ba6bd55

### General data

Colour	grey	Housing main material	AL-Si 12
Type of mounting	Floor-mounted, Wall mounting	Protection degree	IP67
Plugging cycles	750		

### General standards

Connector standard	IEC 61076-3-106 Var. 4
--------------------	------------------------

### Classifications

ETIM 8.0	EC002597	ETIM 9.0	EC002597
ETIM 10.0	EC002597	ECLASS 14.0	27-44-03-18
ECLASS 15.0	27-44-03-18		

Dimensioned drawing



Drawing

