


HDC CFM 10 3F

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

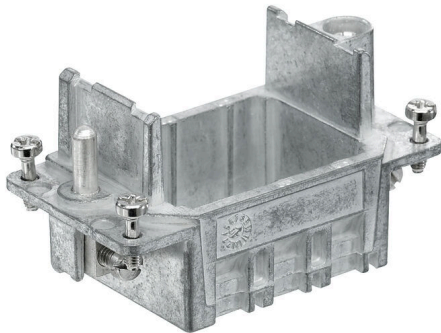

The sturdy CR10 module frames are available in polycarbonate or die-cast zinc.

The frames are designed so that 3 individual modules or corresponding double modules can be installed. The CR10 frames are designed to fit the size-4 housings.

General ordering data

| | |
|------------|--|
| Version | Heavy-duty connectors, HDC insert, ConCept frame |
| Order No. | 1983860000 |
| Type | HDC CFM 10 3F |
| GTIN (EAN) | 4032248688999 |
| Qty. | 1 items |

HDC CFM 10 3F

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E92202

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Depth | 64 mm | Depth (inches) | 2.5197 inch |
| Height | 35 mm | Height (inches) | 1.378 inch |
| Width | 34 mm | Width (inches) | 1.3386 inch |
| Net weight | 76.88 g | | |

Temperatures

Limit temperature -40 °C ... 125 °C

Environmental Product Compliance

RoHS Compliance Status Compliant without exemption

REACH SVHC No SVHC above 0.1 wt%

ConCept Pneumatic module

Colour Silver grey

Dimensions

| | | | |
|------------------|-------|-------------------|-------|
| Width | 34 mm | Total length base | 64 mm |
| Height of socket | 35 mm | | |

General data

| | | | |
|--------------------|--------------|---------------------------------------|---------------|
| Tightening torque | 0.5 Nm | Installation size | 4 |
| Colour | Silver grey | Tightening torque, max. PE connection | 1.5 Nm |
| Type | Female | Tightening torque, min. PE connection | 0.5 Nm |
| Basic material | Diecast zinc | Series | ConCept frame |
| Free from halogens | false | Low smoke acc. DIN EN 45545-2 | Yes |
| BG | 4 | | |

Connection data PE

| | | | |
|---------------------------------------|------------------|---------------------------------------|--------|
| Connection type PE | Screw connection | Tightening torque, max. PE connection | 1.5 Nm |
| Tightening torque, min. PE connection | 0.5 Nm | | |

Version

| | | | |
|-------------------|---|----------------|--------------|
| Installation size | 4 | Basic material | Diecast zinc |
| BG | 4 | | |

Technical data

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC000437 | ETIM 9.0 | EC000437 |
| ETIM 10.0 | EC000437 | ECLASS 14.0 | 27-44-02-02 |
| ECLASS 15.0 | 27-44-02-02 | | |