

RSS110060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Product image



Similar to illustration

Individual relays for TERMSERIES

- Electromechanical relays
- Different contact materials

General ordering data

Version	TERMSERIES, Relay, Number of contacts: 1, CO contact AgSnO, Rated control voltage: 60 V DC, Continuous current: 6 A, Plug-in connection, Test button available: No
Order No.	1984120000
Type	RSS110060
GTIN (EAN)	4050118377682
Qty.	20 items

RSS110060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS Conform

UL File Number Search [UL Website](#)

Certificate No. (cURus) E223474

Dimensions and weights

Depth	15 mm	Depth (inches)	0.5906 inch
Height	28 mm	Height (inches)	1.1024 inch
Width	5 mm	Width (inches)	0.1968 inch
Net weight	5 g		

Temperatures

Storage temperature	-40 °C...85 °C	Ambient temperature	-40 °C...85 °C
Operating temperature			

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Rated data UL

Certificate No. (cURus)	E223474
-------------------------	---------

Control side

Rated control voltage	60 V DC	Rated current DC	3 mA
Power rating	180 mW	Coil resistance	20570 Ω ± 10 %
Status indicator	No		

Load side

Rated switching voltage	250 V AC	Max. switching frequency at rated load	0.1 Hz
Max. switching voltage, AC	250 V	Max. switching voltage, DC	250 V
Inrush current	30 A / 20 ms	AC switching capacity (resistive), max.	1500 VA
DC switching capacity (resistive), max.	144 W @ 24 V	Switch-on delay	<8 ms
Switch-off delay	<4 ms	Contact type	1 CO contact (AgSnO)
Min. switching power	100 mA @ 12 V		

General data

Test button available	No	Mechanical switch position indicator	No
Colour	white		

Insulation coordination

Clearance and creepage distances for control side - load side	≥ 6 mm	Dielectric strength for control side - load side	4 kVeff / 1 Min.
Dielectric strength of open contact	1 kVeff / 1 min	Impulse withstand voltage	6 kV (1.2/50 μs)
Protection degree	IP67		

Creation date 04.05.2026 06:07:42 MEZ

Catalogue status / Drawings

Technical data**Further details of approvals / standards**

Certificate No. (VDE)	40029391	Certificate No. (cURus)	E223474
-----------------------	----------	-------------------------	---------

Connection data

Wire connection method	Plug-in connection
------------------------	--------------------

Classifications

ETIM 8.0	EC001437	ETIM 9.0	EC001437
ETIM 10.0	EC001437	ECLASS 14.0	27-37-16-01
ECLASS 15.0	27-37-16-01		

Wiring diagram



View of Pins from below

Dimensional drawing



Miscellaneous

Type code electromechanical relay (TERMSERIES)



Type codes

RSS110060

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Screw connection




TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRS 60VUC 1CO EMPTY	Version	
Order No.	1123280000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 60 V UC ±10 %, Continuous current: 10 A, Screw connection	
GTIN (EAN)	4032248905270		
Qty.	10 ST		

Tension clamp connection

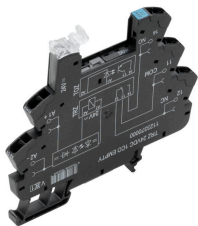


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRZ 60VUC 1CO EMPTY	Version	
Order No.	1123400000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 60 V UC ±10 %, Continuous current: 10 A, Tension-clamp connection	
GTIN (EAN)	4032248905546		
Qty.	10 ST		

PUSH IN connection

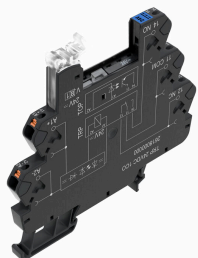

TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRP 60VUC 1CO EMPTY	Version	
Order No.	2618900000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 60 V UC ±10 %, Continuous current: 10 A, PUSH IN	
GTIN (EAN)	4050118669930		
Qty.	10 ST		

RSS110060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Screw connection

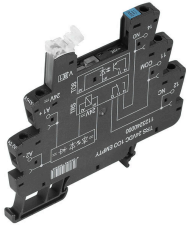


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRS 120VAC RC 1CO EMPTY	Version	
Order No.	1123310000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V AC \pm 10 %, Continuous current: 10 A, Screw connection	
GTIN (EAN)	4032248905317		
Qty.	10 ST		

Tension clamp connection

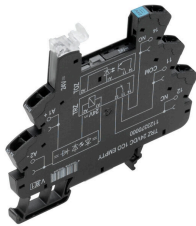


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRZ 120VAC RC 1CO EMPTY	Version	
Order No.	1123430000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V AC \pm 10 %, Continuous current: 10 A, Tension-clamp connection	
GTIN (EAN)	4032248905188		
Qty.	10 ST		

PUSH IN connection

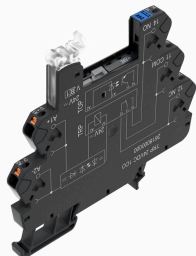

TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRP 120VAC RC 1CO EMPTY	Version	
Order No.	2618880000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V AC \pm 10 %, Continuous current: 10 A, PUSH IN	
GTIN (EAN)	4050118669954		
Qty.	10 ST		

RSS110060

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Screw connection




TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRS 120VUC 1CO EMPTY	Version	
Order No.	1123290000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, Screw connection	
GTIN (EAN)	4032248905461		
Qty.	10 ST		

Tension clamp connection

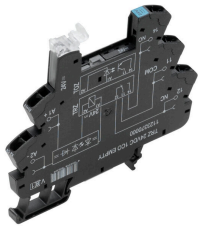


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRZ 120VUC 1CO EMPTY	Version	
Order No.	1123410000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, Tension-clamp connection	
GTIN (EAN)	4032248905690		
Qty.	10 ST		

PUSH IN connection

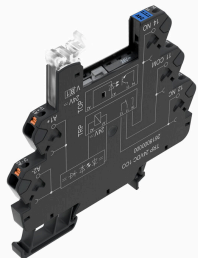

TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRP 120VUC 1CO EMPTY	Version	
Order No.	2618950000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, PUSH IN	
GTIN (EAN)	4050118667585		
Qty.	10 ST		

RSS110060

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Screw connection




TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRS 230VAC RC 1CO EMPTY	Version	
Order No.	1123320000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 230 V AC \pm 10 %, Continuous current: 10 A, Screw connection	
GTIN (EAN)	4032248905522		
Qty.	10 ST		

Tension clamp connection

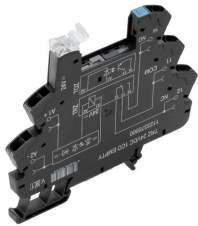


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRZ 230VAC RC 1CO EMPTY	Version	
Order No.	1123440000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 230 V AC \pm 10 %, Continuous current: 10 A, Tension-clamp connection	
GTIN (EAN)	4032248905171		
Qty.	10 ST		

PUSH IN connection

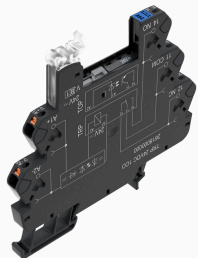

TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRP 230VAC RC 1CO EMPTY	Version	
Order No.	2618890000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 230 V AC \pm 10 %, Continuous current: 10 A, PUSH IN	
GTIN (EAN)	4050118669947		
Qty.	10 ST		

RSS110060

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

Accessories

Screw connection

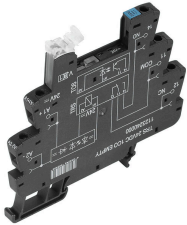


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRS 230VUC 1CO EMPTY	Version	
Order No.	1123300000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated	
GTIN (EAN)	4032248905515	control voltage: 230 V UC \pm 10%, Continuous current: 10 A, Screw	
Qty.	10 ST	connection	

Tension clamp connection

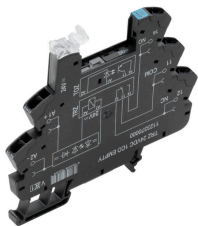


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRZ 230VUC 1CO EMPTY	Version	
Order No.	1123420000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated	
GTIN (EAN)	4032248905683	control voltage: 230 V UC \pm 10%, Continuous current: 10 A, Tension-	
Qty.	10 ST	clamp connection	

PUSH IN connection

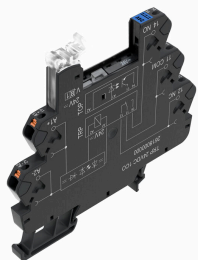

TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRP 230VUC 1CO EMPTY	Version	
Order No.	2618960000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated	
GTIN (EAN)	4050118667578	control voltage: 230 V UC \pm 10%, Continuous current: 10 A, PUSH IN	
Qty.	10 ST		


RSS110060

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Counterpart

Screw connection

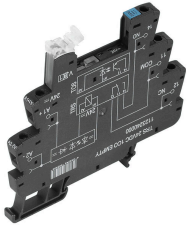


TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRS 60VUC 1CO EMPTY	Version
Order No.	1123280000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 60 V UC $\pm 10\%$, Continuous current: 10 A, Screw connection
GTIN (EAN)	4032248905270	
Qty.	10 ST	
Type	TRS 120VUC 1CO EMPTY	Version
Order No.	1123290000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, Screw connection
GTIN (EAN)	4032248905461	
Qty.	10 ST	
Type	TRS 230VUC 1CO EMPTY	Version
Order No.	1123300000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 230 V UC $\pm 10\%$, Continuous current: 10 A, Screw connection
GTIN (EAN)	4032248905515	
Qty.	10 ST	
Type	TRS 120VAC RC 1CO EMPTY	Version
Order No.	1123310000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 120 V AC $\pm 10\%$, Continuous current: 10 A, Screw connection
GTIN (EAN)	4032248905317	
Qty.	10 ST	
Type	TRS 230VAC RC 1CO EMPTY	Version
Order No.	1123320000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 230 V AC $\pm 10\%$, Continuous current: 10 A, Screw connection
GTIN (EAN)	4032248905522	
Qty.	10 ST	

Tension clamp connection

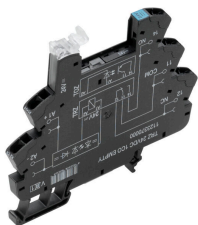

TERMSERIES empty sockets with:

- 1 UC contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRZ 60VUC 1CO EMPTY	Version
Order No.	1123400000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated control voltage: 60 V UC $\pm 10\%$, Continuous current: 10 A, Tension-clamp connection
GTIN (EAN)	4032248905546	
Qty.	10 ST	

RSS110060

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Counterpart

Type	TRZ 120VUC 1CO EMPTY	Version
Order No.	1123410000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905690	control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, Tension-
Qty.	10 ST	clamp connection
Type	TRZ 230VUC 1CO EMPTY	Version
Order No.	1123420000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905683	control voltage: 230 V UC $\pm 10\%$, Continuous current: 10 A, Tension-
Qty.	10 ST	clamp connection
Type	TRZ 120VAC RC 1CO EMPTY	Version
Order No.	1123430000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905188	control voltage: 120 V AC $\pm 10\%$, Continuous current: 10 A, Tension-
Qty.	10 ST	clamp connection
Type	TRZ 230VAC RC 1CO EMPTY	Version
Order No.	1123440000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4032248905171	control voltage: 230 V AC $\pm 10\%$, Continuous current: 10 A, Tension-
Qty.	10 ST	clamp connection

PUSH IN connection



TERMSERIES empty sockets with:

- 1 CO contact
- Unique multi-voltage input from 24 to 230 V UC
- Input voltages with coloured marking: DC: blue, UC: white
- Due to high-quality design and no sharp edges no risk of injuries during installation
- Partition plates for optical separation and reinforcement of insulation

General ordering data

Type	TRP 60VUC 1CO EMPTY	Version
Order No.	2618900000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118669930	control voltage: 60 V UC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 ST	
Type	TRP 120VUC 1CO EMPTY	Version
Order No.	2618950000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118667585	control voltage: 120 V UC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 ST	
Type	TRP 230VUC 1CO EMPTY	Version
Order No.	2618960000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118667578	control voltage: 230 V UC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 ST	
Type	TRP 120VAC RC 1CO EMPTY	Version
Order No.	2618880000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118669954	control voltage: 120 V AC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 ST	
Type	TRP 230VAC RC 1CO EMPTY	Version
Order No.	2618890000	TERMSERIES, Relay socket, Number of contacts: 1, CO contact, Rated
GTIN (EAN)	4050118669947	control voltage: 230 V AC $\pm 10\%$, Continuous current: 10 A, PUSH IN
Qty.	10 ST	