

## PZ 10 SQR ZERT

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)



Crimping tools for wire end ferrules, with and without plastic collars

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

### General ordering data

Version	0.14mm <sup>2</sup> , 10mm <sup>2</sup> , Square crimp
Order No.	<a href="#">1989310000</a>
Type	PZ 10 SQR ZERT
GTIN (EAN)	4050118373660
Qty.	1 items

**PZ 10 SQR ZERT**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Dimensions and weights**

Width	195 mm	Width (inches)	7.6772 inch
Net weight	510 g		

**Environmental Product Compliance**

RoHS Compliance Status	Not affected
REACH SVHC	Lead 7439-92-1
SCIP	2159813b-98fd-4068-b62a-bc89a046c012

**Technical data**

Description of article	(1)Crimping tool	Version	Mechanical, without interchangeable inserts
------------------------	------------------	---------	---

**Description of contact**

Type of contact	Wire-end ferrules with/without plastic collars	Conductor cross-section, max. AWG	AWG 8
Conductor cross-section, min. AWG	AWG 26	Crimping range, max.	10 mm <sup>2</sup>
Crimping range, min.	0.14 mm <sup>2</sup>		


**tool data crimping**

Drive	mechanical	Wire end ferrules cross-section, max.	10 mm <sup>2</sup>
Wire end ferrules cross-section, min.	0.14 mm <sup>2</sup>	Crimping type/profile	Square crimp

**Classifications**

ETIM 8.0	EC000168	ETIM 9.0	EC000168
ETIM 10.0	EC000168	ECLASS 14.0	21-04-38-11
ECLASS 15.0	21-04-38-11		

**Drawings**

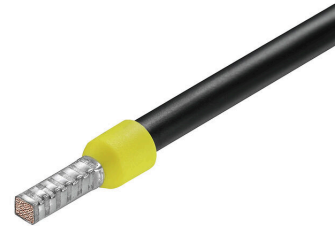

**Example of use**

