

PZ 10 HEX ZERT**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Crimping tools for wire end ferrules, with and without plastic collars

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

General ordering data

Version	0.25mm ² , 10mm ² , Hexagonal crimp
Order No.	1989320000
Type	PZ 10 HEX ZERT
GTIN (EAN)	4050118373677
Qty.	1 items

PZ 10 HEX ZERT

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Dimensions and weights

Width	195 mm	Width (inches)	7.6772 inch
Net weight	510 g		

Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	Lead 7439-92-1
SCIP	2159813b-98fd-4068-b62a-bc89a046c012

Technical data

Description of article	(1)Crimping tool	Version	Mechanical, without interchangeable inserts
------------------------	------------------	---------	---

Description of contact


Type of contact	Wire-end ferrules with/ without plastic collars	Conductor cross-section, max. AWG	AWG 8
Conductor cross-section, min. AWG	AWG 24	Crimping range, max.	10 mm ²
Crimping range, min.	0.25 mm ²		

tool data crimping

Drive	mechanical	Wire end ferrules cross-section, max.	10 mm ²
Wire end ferrules cross-section, min.	0.25 mm ²	Crimping type/profile	Hexagonal crimp

Classifications

ETIM 8.0	EC000168	ETIM 9.0	EC000168
ETIM 10.0	EC000168	ECLASS 14.0	21-04-38-11
ECLASS 15.0	21-04-38-11		

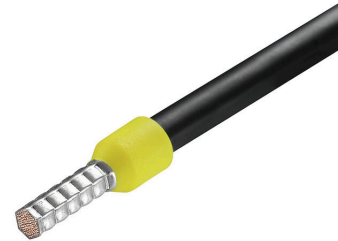

Example of use



Example of use



Example of use

