


## ES EPG 45 HEX 150

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

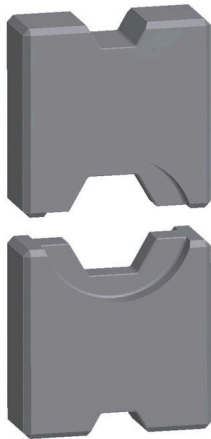

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

Version	150mm <sup>2</sup> , Hexagonal crimp
Order No.	<a href="#">1994540000</a>
Type	ES EPG 45 HEX 150
GTIN (EAN)	4050118379778
Qty.	1 items

**ES EPG 45 HEX 150**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Dimensions and weights**

Depth	12 mm	Depth (inches)	0.4724 inch
Height	60 mm	Height (inches)	2.3622 inch
Width	30 mm	Width (inches)	1.1811 inch
Net weight	129 g		

**Environmental Product Compliance**

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

**Crimp inserts**

Identification number	22	Crimping width	5 mm
Crimp cross-section copper	150	Crimping width in mm	5

**Description of contact**

Conductor cross-section, max. AWG	5/0	Conductor cross-section, min. AWG	5/0
Crimping range, max.	150 mm <sup>2</sup>		

**tool data crimping**

Crimping type/profile	Hexagonal crimp
Cable lug cross section	nominal 150 mm <sup>2</sup>

**Classifications**

ETIM 8.0	EC001282	ETIM 9.0	EC001282
ETIM 10.0	EC001282	ECLASS 14.0	21-04-90-90
ECLASS 15.0	21-04-90-90		