 



## HDC XX5E01 FOXXXXX-0100

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

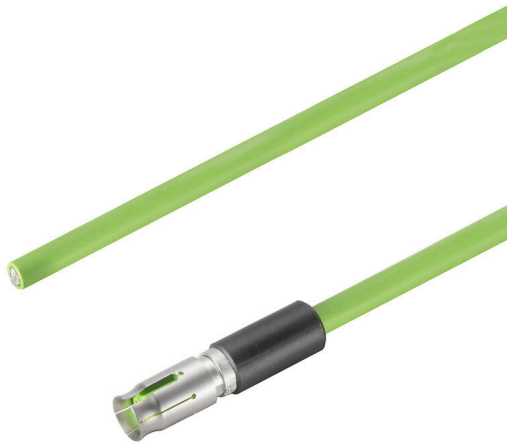

### Compact

The new two-pole bus module is extremely compact and can accommodate both megabit and gigabit data inserts. It enables the connection of 2 Gigabit Cat 6A cables (10 gigabit) to one module.

### General ordering data

Version	Data use
Order No.	<a href="#">2003920100</a>
Type	HDC XX5E01 FOXXXXX-0100
GTIN (EAN)	4050118464450
Qty.	1 items

**HDC XX5E01 FOXXXXX-0100**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

Diameter 6.5 mm Net weight 73.04 g

**Temperatures**

Limit temperature -30 °C ... 90 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant with exemption  
 RoHS Exemption (if applicable/known) 6c  
 REACH SVHC Lead 7439-92-1  
 SCIP 2ac5c63f-7f5e-465a-860d-49cfb7bbe5b5

**General data**

Number of poles	4	Cable length	1 m
Coding	D-coded	Contact surface	Au (Gold)
Transmission rate	100 MBit/s	Insulation resistance	≥ 108 Ω
Category	Cat. 5e	Nominal voltage	250 V
Nominal current	4 A	Plugging cycles	≥ 100
Type	Female	Pollution severity	2
Opposite side version	open	Module side version	Female

**Cable technical specifications**

Cable length	1 m
Sheathing colour	green
Shielded	Yes
Halogen	No, halogen-free
Insulation	PE
Sheath material	PUR
Colour coding	white, yellow, blue, orange
Outside diameter	Diameter 6.5 mm
	Signs ±
	Tolerance 0.2
Outside diameter	6.5 mm ± 0.2

**Classifications**

ETIM 8.0	EC002599	ETIM 9.0	EC002599
ETIM 10.0	EC002599	ECLASS 14.0	27-06-03-07
ECLASS 15.0	27-06-03-07		

**Drawings**

---

---

	M12
yellow	1
white	2
orange	3
blue	4

---

---