

ESG 6/17 MM GE


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

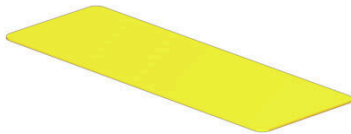

Guaranteed long service life: ESG

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

| | |
|------------|--|
| Version | ESG, Device markers, 6 x 17 mm, yellow |
| Order No. | 2005110000 |
| Type | ESG 6/17 MM GE |
| GTIN (EAN) | 4050118390827 |
| Qty. | 3000 items |

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|--------|-----------------|-------------|
| Depth | 0.1 mm | Depth (inches) | 0.0039 inch |
| Height | 6 mm | Height (inches) | 0.2362 inch |
| Width | 17 mm | Width (inches) | 0.6693 inch |
| Net weight | 0.04 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -40...120 °C |
|-----------------------------|--------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | | |
|--------------------------------------|--|------------|--|
| Adhesive | Acrylate adhesive | | |
| Version | Self-adhesive, halogen-free | | |
| Width | 17 mm | | |
| UL 94 flammability rating | V-0 | | |
| Operating temperature range, max. | 120 °C | | |
| Operating temperature range, min. | -40 °C | | |
| Colour | yellow | | |
| Halogen | No | | |
| Basic material | Polyester | | |
| Printed characters | without | | |
| Number of markers per packaging unit | Form of supply | Label reel | |
| | Number of markers per combination | 3000 | |
| Approval acc. to UL 969 | Yes | | |
| compatible printer | THM MULTIMARK , THM MULTIMARK PLUS | | |
| Number of markers per combination | 1 Label reel = 3000 Device markers | | |
| Operating temperature range | -40...120 °C | | |
| Number per roll | 3000 | | |

Device markers

| | |
|---------|----|
| Halogen | No |
|---------|----|

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001288 | ETIM 9.0 | EC001288 |
| ETIM 10.0 | EC001288 | ECLASS 14.0 | 27-28-11-04 |
| ECLASS 15.0 | 27-28-11-04 | | |

Drawings

