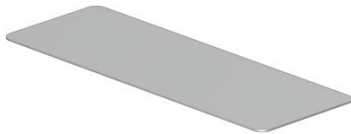


ESG 6/17 MM GR**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Guaranteed long service life: ESG

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

Version	ESG, Device markers, 6 x 17 mm, grey
Order No.	2005120000
Type	ESG 6/17 MM GR
GTIN (EAN)	4050118390742
Qty.	3000 items

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Depth	0.1 mm	Depth (inches)	0.0039 inch
Height	6 mm	Height (inches)	0.2362 inch
Width	17 mm	Width (inches)	0.6693 inch
Net weight	0.04 g		

Temperatures

Operating temperature range	-40...120 °C
-----------------------------	--------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

General data

Adhesive	Acrylate adhesive	
Version	Self-adhesive, halogen-free	
Width	17 mm	
UL 94 flammability rating	V-0	
Operating temperature range, max.	120 °C	
Operating temperature range, min.	-40 °C	
Colour	grey	
Halogen	No	
Basic material	Polyester	
Printed characters	without	
Number of markers per packaging unit	Form of supply	Label reel
	Number of markers per combination	3000
Approval acc. to UL 969	Yes	
compatible printer	THM MULTIMARK , THM MULTIMARK PLUS	
Number of markers per combination	1 Label reel = 3000 Device markers	
Operating temperature range	-40...120 °C	
Number per roll	3000	

Device markers

Halogen	No
---------	----

Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

Drawings



ESG 6/17 MM GR
Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

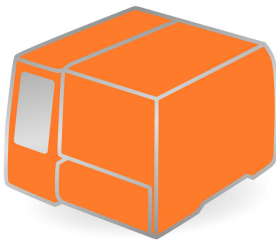
Germany

www.weidmueller.com
Accessories
Ink ribbons


These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

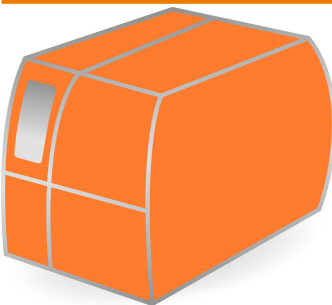
Type	RIBBON MM 76/360 SW	Version	
Order No.	2005080000	Ink ribbon	
GTIN (EAN)	4050118389951		
Qty.	1 ST		

THM MULTIMARK


These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK ROLLER 115	Version	
Order No.	1357420000		
GTIN (EAN)	4050118160314		
Qty.	1 ST		

THM MULTIMARK PLUS


These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	MULTIMARK PLUS ROLLER 1...	Version	
Order No.	2672590000		
GTIN (EAN)	4050118708097		
Qty.	1 ST		