


## ESG 6/17 MM SW

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

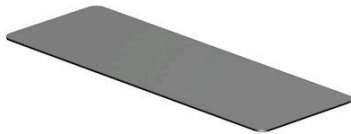

### Guaranteed long service life: ESG

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

### Your benefits with MultiMark

- “Different materials for various requirements”
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

### General ordering data

Version	ESG, Device markers, 6 x 17 mm, black
Order No.	<a href="#">2005130000</a>
Type	ESG 6/17 MM SW
GTIN (EAN)	4050118390612
Qty.	3000 items

## ESG 6/17 MM SW

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

ROHS	Conform
------	---------

### Dimensions and weights

Depth	0.1 mm	Depth (inches)	0.0039 inch
Height	6 mm	Height (inches)	0.2362 inch
Width	17 mm	Width (inches)	0.6693 inch
Net weight	0.04 g		

### Temperatures

Operating temperature range	-40...120 °C
-----------------------------	--------------

### Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

### General data

Adhesive	Acrylate adhesive		
Version	Self-adhesive, halogen-free		
Width	17 mm		
UL 94 flammability rating	V-0		
Operating temperature range, max.	120 °C		
Operating temperature range, min.	-40 °C		
Colour	black		
Halogen	No		
Basic material	Polyester		
Printed characters	without		
Number of markers per packaging unit	Form of supply	Label reel	
	Number of markers per combination	3000	
Approval acc. to UL 969	Yes		
compatible printer	<a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a>		
Number of markers per combination	1 Label reel = 3000 Device markers		
Operating temperature range	-40...120 °C		
Number per roll	3000		

### Device markers

Halogen	No
---------	----

### Classifications

ETIM 8.0	EC001288	ETIM 9.0	EC001288
ETIM 10.0	EC001288	ECLASS 14.0	27-28-11-04
ECLASS 15.0	27-28-11-04		

**Drawings**



## ESG 6/17 MM SW

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	RIBBON MM 84/300 WS	Version	
Order No.	<a href="#">2005040000</a>	Ink ribbon	
GTIN (EAN)	4050118390025		
Qty.	1 ST		

### THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	MULTIMARK ROLLER 115	Version	
Order No.	<a href="#">1357420000</a>		
GTIN (EAN)	4050118160314		
Qty.	1 ST		

### THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

Type	MULTIMARK PLUS ROLLER 1...	Version	
Order No.	<a href="#">2672590000</a>		
GTIN (EAN)	4050118708097		
Qty.	1 ST		