


ELS 16/40 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

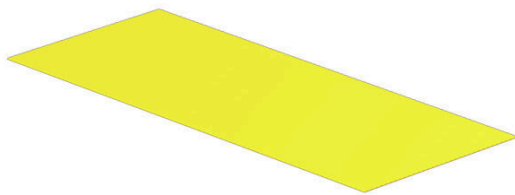

ELS

ELS tags are special and non-adhesive insertable labels for WKM cable markers or for group tag carriers. The matt, thin but tear-resistant polyester provides very good labelling and excellent readability. Used in combination with water-repellent WKM sleeves, the solution guarantees particularly long-lasting identification of cables even in harsh environments.

General ordering data

| | |
|------------|---|
| Version | ELS, Insert markers, 7 - 115 mm, 40 x 16 mm, yellow |
| Order No. | 2005260000 |
| Type | ELS 16/40 MM GE |
| GTIN (EAN) | 4050118389975 |
| Qty. | 2000 items |

ELS 16/40 MM GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

| | |
|------|---------|
| ROHS | Conform |
|------|---------|

Dimensions and weights

| | | | |
|------------|---------|-----------------|-------------|
| Depth | 0.14 mm | Depth (inches) | 0.0055 inch |
| Height | 40 mm | Height (inches) | 1.5748 inch |
| Width | 16 mm | Width (inches) | 0.6299 inch |
| Net weight | 0.17 g | | |

Temperatures

| | |
|-----------------------------|--------------|
| Operating temperature range | -40...150 °C |
|-----------------------------|--------------|

Environmental Product Compliance

| | |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC | No SVHC above 0.1 wt% |

General data

| | | | |
|-----------------------------------|--|-----------------------------------|--------------|
| Type of printing | neutral | Version | halogen-free |
| Width | 16 mm | UL 94 flammability rating | HB |
| Operating temperature range, max. | 150 °C | Operating temperature range, min. | -40 °C |
| Colour | yellow | Halogen | No |
| Basic material | Polyester | Printed characters | without |
| compatible printer | THM MULTIMARK , THM MULTIMARK PLUS | Operating temperature range | -40...150 °C |
| Number per roll | 2000 | | |


Conductor and cable markers

| | | | |
|----------------------|------------|----------------------------------|---------------------|
| Halogen | No | Conductor cross-section, max. | 150 mm ² |
| Conductor O.D., max. | 115 mm | Conductor O.D., min. | 7 mm |
| Conductor O.D. | 7 - 115 mm | Cross-section for connected wire | 150 mm ² |

Classifications

| | | | |
|-------------|-------------|-------------|-------------|
| ETIM 8.0 | EC001530 | ETIM 9.0 | EC001530 |
| ETIM 10.0 | EC001530 | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 | | |

Drawings

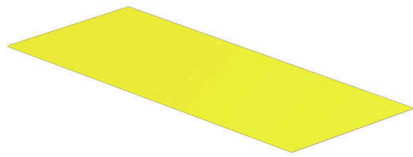

ELS 16/40 MM GE

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

WKM for inlay tags



The halogen-free, transparent pocket of the WKM offers outstanding protection against environmental influences. Thanks to firm fixation with cable ties, it is suitable for almost all wire cross-sections.

The pre-printed tags are simply inserted into the WKM holder and secured with a clip. WKM cable markers are the right solution for maximum efficiency in on-site marking. Your advantage when using WKM cables

- Paper and polyester labels can be printed individually with conventional office printers
- The robust design in combination with MultiCard ELS tags guarantees maximum protection against environmental influences

General ordering data

| | | | |
|------------|----------------------------|--|--|
| Type | WKM 18/43 | Version | |
| Order No. | 1610700000 | WKM, Conductor and cable markers, 7 - 115 mm, 43 x 18 mm, Wire | |
| GTIN (EAN) | 4008190204488 | and cable markers, Transparent | |
| Qty. | 50 ST | | |

Ink ribbons




These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|------------|--|
| Type | RIBBON MM 110/360 SW | Version | |
| Order No. | 2005070000 | Ink ribbon | |
| GTIN (EAN) | 4050118390049 | | |
| Qty. | 1 ST | | |

THM MULTIMARK

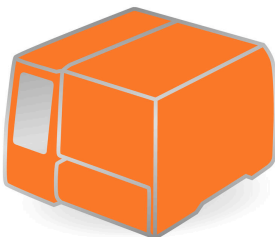

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

ELS 16/40 MM GE

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Accessories**General ordering data**

| | | | |
|------------|----------------------------|---------|--|
| Type | MULTIMARK ROLLER 115 | Version | |
| Order No. | 1357420000 | | |
| GTIN (EAN) | 4050118160314 | | |
| Qty. | 1 ST | | |

THM MULTIMARK PLUS

These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

| | | | |
|------------|----------------------------|---------|--|
| Type | MULTIMARK PLUS ROLLER 1... | Version | |
| Order No. | 2672590000 | | |
| GTIN (EAN) | 4050118708097 | | |
| Qty. | 1 ST | | |