

SAKQ 70/2


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

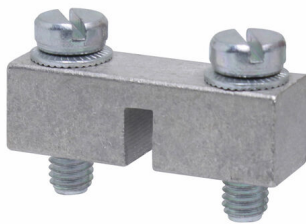

General ordering data

Version	Cross-connector (terminal), grey, 192 A, Number of poles: 2, Pitch in mm (P): 20.50, Width: 9.5 mm
Order No.	2047280000
Type	SAKQ 70/2
GTIN (EAN)	4050118451351
Qty.	5 items
Local product	Only available in certain countries

SAKQ 70/2

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

General ordering data

Local product	Only available in certain countries
---------------	-------------------------------------

Dimensions and weights

Depth	19.6 mm	Depth (inches)	0.7717 inch
Height	30.5 mm	Height (inches)	1.2008 inch
Width	9.5 mm	Width (inches)	0.374 inch
Net weight	23.58 g		

Temperatures

Storage temperature	-25 °C...55 °C	Ambient temperature	-5 °C...40 °C
---------------------	----------------	---------------------	---------------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Material data

Colour	grey
--------	------

Additional technical data

Explosion-tested version	No
--------------------------	----

Dimensions

Pitch in mm (P)	20.50 mm
-----------------	----------

General

Number of poles	2
-----------------	---

Rating data

Rated voltage	400 V	Nominal current	192 A
---------------	-------	-----------------	-------

Classifications

ETIM 8.0	EC000489	ETIM 9.0	EC000489
ETIM 10.0	EC000489	ECLASS 14.0	27-25-03-03
ECLASS 15.0	27-25-03-03		