

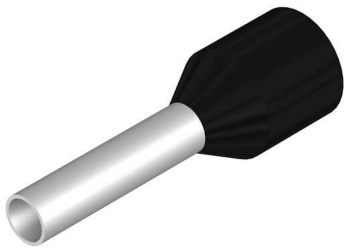
**H1,5/16 DS SW****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

**Similar to illustration**

- Polypropylene conical cable entry funnel
  - Heat-resistant up to 105°C
- For conductors from 0.5 – 10.0 mm<sup>2</sup> (AWG 20-7)  
Material: E-Cu, tin galvanised  
Dimensional tolerance acc. to DIN 46228 sect. 4

**General ordering data**

Version	Wire-end ferrule, Standard, 12 mm, 10 mm, black
Order No.	<a href="#">2092490000</a>
Type	H1,5/16 DS SW
GTIN (EAN)	4050118422047
Qty.	500 items
Packaging	loose

H1,5/16 DS SW

Weidmüller Interface GmbH & Co. KG  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

Technical data

Approvals

Approvals



ROHS	Conform
UL File Number Search	<a href="#">UL Website</a>
Certificate No. (UR)	E354986
Certificate no. (cULus)	E499744

Dimensions and weights

Net weight	0.13 g
------------	--------

Environmental Product Compliance

RoHS Compliance Status	Compliant without exemption
REACH SVHC	No SVHC above 0.1 wt%

Technical data

Description of article	Wire end ferrule with plastic collar, special size, black	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Contact surface diameter (D1)	1.7 mm	Contact surface length (L2)	10 mm
Collar diameter (D2)	4 mm	Plastic collar thickness (S2)	0.25 mm
L1 in mm	16.00 mm	Wire connection cross section AWG, max.	AWG 16
Metal sleeve thickness (S1)	0.15 mm	Stripping length	12 mm
Conductor cross-section	1.5 mm <sup>2</sup>	Colour code	DIN

Classifications

ETIM 8.0	EC000005	ETIM 9.0	EC000005
ETIM 10.0	EC000005	ECLASS 14.0	27-40-02-01
ECLASS 15.0	27-40-02-01		

Drawing

