

PAC-HE16-F-HF-1M


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

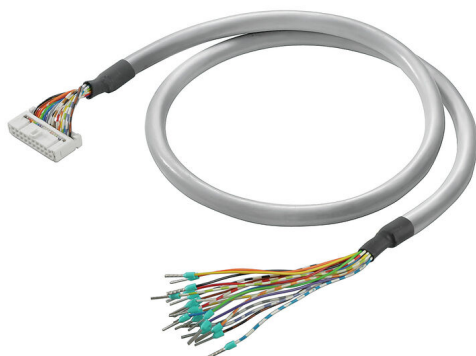

Similar to illustration

General ordering data

Order No.	2425710010
Type	PAC-HE16-F-HF-1M
GTIN (EAN)	4032248273164
Qty.	1 items

PAC-HE16-F-HF-1M**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Approvals**

ROHS	Conform
------	---------

Dimensions and weights

Net weight	80.3 g
------------	--------

Temperatures

Storage temperature	-10...60 °C	Operating temperature	-10...50
---------------------	-------------	-----------------------	----------

Environmental Product Compliance

RoHS Compliance Status	Compliant
REACH SVHC	No SVHC above 0.1 wt%

General Data

Cable length	1 m	Suitable for	Digital signals
Cable	Cable LIHH	Interface connector	FLAT CABLE CONNECTOR HE10 16P
Number of poles, min.	16-pole	Connector PLC side	H0.14/10 (FERRULES 0.14mm ²)
Wire cross-section	0.14 mm ²		

Electrical Data

Total current, max.	3 A	Permissible current strength per path, max.	1 A
Rated voltage	≤ 60 V DC ≤ 25 V AC	Resistance	≤ 150 mΩ/m
Operating voltage	≤ 60 V DC ≤ 25 V AC	Capacity wire / wires	300 pF/m
Capacity wire / shield	300 pF/m		

Classifications

ETIM 8.0	EC000237	ETIM 9.0	EC000237
ETIM 10.0	EC000237	ECLASS 14.0	27-24-22-20
ECLASS 15.0	27-24-22-20		