

**HS 3.2-9.5/25 MM W**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com



The heat-shrinkable sleeve is printable on 2 sides and can be used for marking and insulating cables and wires. The flexible, heat-shrink material enables a firm, perfect fit around the conductor and therefore saves space.

**General ordering data**

|            |  |
|------------|--|
| Version    | Conductor and cable markers, 3.2 - 9.5 mm, 25.4 x 15.1 mm, white |
| Order No.  | <a href="#">2437670000</a>                                       |
| Type       | HS 3.2-9.5/25 MM W   |
| GTIN (EAN) | 4050118461152  |
| Qty.       | 1000 items   |

## HS 3.2-9.5/25 MM W

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Approvals

|      |         |
|------|---------|
| ROHS | Conform |
|------|---------|

### Dimensions and weights

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Depth      | 0.77 mm | Depth (inches)  | 0.0303 inch |
| Height     | 25.4 mm | Height (inches) | 1 inch      |
| Width      | 15.1 mm | Width (inches)  | 0.5945 inch |
| Net weight | 0.51 g  |                 |             |

### Temperatures

|                             |              |
|-----------------------------|--------------|
| Operating temperature range | -55...135 °C |
|-----------------------------|--------------|

### Environmental Product Compliance

|                        |                             |
|------------------------|-----------------------------|
| RoHS Compliance Status | Compliant without exemption |
| REACH SVHC             | No SVHC above 0.1 wt%       |

### General data

|                                   |   |                                   |  |
|-----------------------------------|---|-----------------------------------|--|
| Type of printing                  | neutral   | Width                             | 15.1 mm  |
| Operating temperature range, max. | 135 °C  | Operating temperature range, min. | -55 °C   |
| Colour                            | white   | Halogen                           | Yes  |
| Basic material                    | Polyolefine   | Printed characters                | without  |
| Recommended industries            | Plant manufacture, Energy,<br>Device manufacturer,<br>Machinery | compatible printer                | <a href="#">THM MULTIMARK</a> , <a href="#">THM MULTIMARK PLUS</a> |
| Operating temperature range       | -55...135 °C  | Number per roll                   | 1000   |

### Conductor and cable markers

|                                   |                        |                               |                    |
|-----------------------------------|------------------------|-------------------------------|--------------------|
| Halogen                           | Yes                    | Conductor cross-section, max. | 16 mm <sup>2</sup> |
| Conductor cross-section, min.     | 4 mm <sup>2</sup>      | Conductor O.D., max.          | 9.5 mm             |
| Conductor O.D., min.              | 3.2 mm                 | Rate of shrinkage             | 3:1                |
| Recommended shrinking temperature | 90 °C                  | Conductor O.D.                | 3.2 - 9.5 mm       |
| Cross-section for connected wire  | 4 - 16 mm <sup>2</sup> |                               |                    |

### Classifications


|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC001530    | ETIM 9.0    | EC001530    |
| ETIM 10.0   | EC001530    | ECLASS 14.0 | 27-28-11-02 |
| ECLASS 15.0 | 27-28-11-02 |             |             |

**HS 3.2-9.5/25 MM W**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

**Drawings**

[www.weidmueller.com](http://www.weidmueller.com)

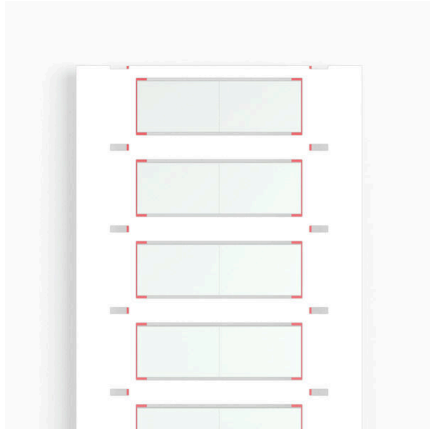

## HS 3.2-9.5/25 MM W

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

[www.weidmueller.com](http://www.weidmueller.com)

## Accessories

### Ink ribbons



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

|            |                            |            |  |
|------------|----------------------------|------------|--|
| Type       | RIBBON MM-HS 60/300 SW     | Version    |  |
| Order No.  | <a href="#">2448880000</a> | Ink ribbon |  |
| GTIN (EAN) | 4050118462944              |            |  |
| Qty.       | 1 ST                       |            |  |

### THM MULTIMARK



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | MULTIMARK ROLLER 115       | Version |  |
| Order No.  | <a href="#">1357420000</a> |         |  |
| GTIN (EAN) | 4050118160314              |         |  |
| Qty.       | 1 ST                       |         |  |

### THM MULTIMARK PLUS



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

#### General ordering data

|            |                            |         |  |
|------------|----------------------------|---------|--|
| Type       | MULTIMARK PLUS ROLLER 1... | Version |  |
| Order No.  | <a href="#">2672590000</a> |         |  |
| GTIN (EAN) | 4050118708097              |         |  |
| Qty.       | 1 ST                       |         |  |