


**WAD 12 MC SDR**

**Weidmüller Interface GmbH & Co. KG**  
Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

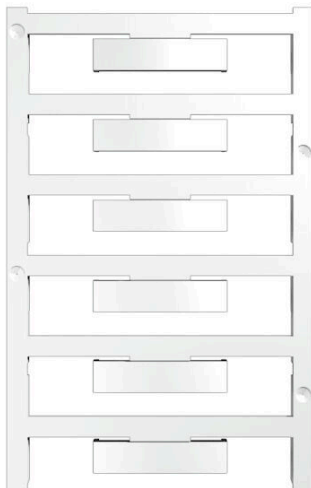

The WAD connector marker is suitable for W-series terminals and for the WEW 35/2 and ZEW 35/2 end brackets. The markers are available as blank markers, with custom printing or standard print with lightning symbol. The WAD MultiCard markers are suitable for labelling with PrintJet CONNECT printers. For custom printing: Please send us a file of our labeling software M-Print PRO or M-Print PRO Online (without installation) for your labeling specifications.

**General ordering data**

|            |   |
|------------|---|
| Version    | Group markers, Cover, 36.2 x 11.9 mm, WDU 16, WDU 35, To customer specification |
| Order No.  | <a href="#">2445 100000</a>   |
| Type       | WAD 12 MC SDR   |
| GTIN (EAN) | 4050118458206   |
| Qty.       | 8 items   |

**WAD 12 MC SDR**

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

**Technical data**

**Approvals**

ROHS Conform

**Dimensions and weights**

|            |         |                 |             |
|------------|---------|-----------------|-------------|
| Height     | 36.2 mm | Height (inches) | 1.4252 inch |
| Width      | 11.9 mm | Width (inches)  | 0.4685 inch |
| Net weight | 1.98 g  |                 |             |

**Temperatures**

Operating temperature range -40...100 °C

**Environmental Product Compliance**

RoHS Compliance Status Compliant without exemption  
 REACH SVHC No SVHC above 0.1 wt%


**General data**

|                                      |                           |           |  |
|--------------------------------------|---------------------------|-----------|--|
| Width                                | 11.9 mm                   |           |  |
| UL 94 flammability rating            | V-2                       |           |  |
| Operating temperature range, max.    | 100 °C                    |           |  |
| Operating temperature range, min.    | -40 °C                    |           |  |
| Colour                               | To customer specification |           |  |
| Halogen                              | No                        |           |  |
| Basic material                       | Polyamide 66              |           |  |
| Printed characters                   | Requires M-Print PRO File |           |  |
| Number of markers per packaging unit | Form of supply            | MultiCard |  |
| Number of markers per combination    | 1 MultiCard = Cover       |           |  |
| Operating temperature range          | -40...100 °C              |           |  |
| Application/manufacturer             | WDU 16, WDU 35            |           |  |

**Classifications**

|             |             |             |             |
|-------------|-------------|-------------|-------------|
| ETIM 8.0    | EC000761    | ETIM 9.0    | EC000761    |
| ETIM 10.0   | EC000761    | ECLASS 14.0 | 27-28-11-01 |
| ECLASS 15.0 | 27-28-11-01 |             |             |

**Drawings**

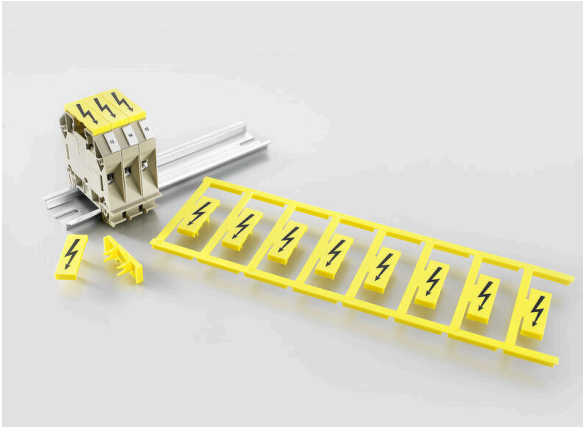

**Drawing**