

## HPG 60

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

[www.weidmueller.com](http://www.weidmueller.com)



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 400 mm<sup>2</sup>
- 360° revolving quick action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- Additional features for APG series:
  - electronic control and monitoring of the crimping process
  - Saving of all crimping cycles and error messages to internal memory
  - Reading of all cycles and error messages via USB

### General ordering data

Version	6mm <sup>2</sup> , 300mm <sup>2</sup> , Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping
Order No.	<a href="#">2453820000</a>
Type	HPG 60
GTIN (EAN)	4050118468427
Qty.	1 items

## HPG 60

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Technical data

### Dimensions and weights

Depth	285 mm	Depth (inches)	11.2204 inch
Height	120 mm	Height (inches)	4.7244 inch
Width	500 mm	Width (inches)	19.685 inch
Length	850 mm	Length (inches)	33.4645 inch
Net weight	5661.92 g		

### Environmental Product Compliance

RoHS Compliance Status	Not affected
REACH SVHC	Lead 7439-92-1

### Technical data

Description of article	Crimping tool 6 - 300 mm <sup>2</sup>		
Pressing force	nominal		60 kN
	max.		60 kN

### Description of contact

Type of contact	DIN 46235 cable lug	Crimping range, max.	300 mm <sup>2</sup>
Crimping range, min.	6 mm <sup>2</sup>		

### tool data crimping

Drive	Manual - hydraulic	Wire end ferrules cross-section, max.	300 mm <sup>2</sup>
Wire end ferrules cross-section, min.	6 mm <sup>2</sup>	Crimping type/profile	Hexagonal crimp, WM crimp, Indent crimp, Trapezoidal crimp, Oval crimping

### Classifications

ETIM 8.0	EC000168	ETIM 9.0	EC000168
ETIM 10.0	EC000168	ECLASS 14.0	21-04-38-11
ECLASS 15.0	21-04-38-11		


## HPG 60

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

### ... for tubular cable lugs

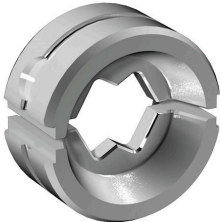

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

Type	ES EPG/HPG 60 WM 6	Version
Order No.	<a href="#">2469380000</a>	Crimping tool insert, 6mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118532937	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 10	Version
Order No.	<a href="#">2469540000</a>	Crimping tool insert, 10mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483819	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 16	Version
Order No.	<a href="#">2469550000</a>	Crimping tool insert, 16mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483833	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 25	Version
Order No.	<a href="#">2469560000</a>	Crimping tool insert, 25mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483840	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 35	Version
Order No.	<a href="#">2469570000</a>	Crimping tool insert, 35mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483826	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 50	Version
Order No.	<a href="#">2469580000</a>	Crimping tool insert, 50mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483864	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 70	Version
Order No.	<a href="#">2469590000</a>	Crimping tool insert, 70mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483857	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 95	Version
Order No.	<a href="#">2469600000</a>	Crimping tool insert, 95mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483895	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 120	Version
Order No.	<a href="#">2469610000</a>	Crimping tool insert, 120mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118484007	
Qty.	1 ST	

## HPG 60

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Accessories

Type	ES EPG/HPG 60 WM 150	Version
Order No.	<a href="#">2469620000</a>	Crimping tool insert, 150mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118483871	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 185	Version
Order No.	<a href="#">2469630000</a>	Crimping tool insert, 185mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118484038	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 240	Version
Order No.	<a href="#">2469640000</a>	Crimping tool insert, 240mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118484052	
Qty.	1 ST	
Type	ES EPG/HPG 60 WM 300	Version
Order No.	<a href="#">2469650000</a>	Crimping tool insert, 300mm <sup>2</sup> , WM crimp
GTIN (EAN)	4050118484045	
Qty.	1 ST	

### ... for crimp cable lugs



- Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts
- extremely fast processing thanks to hydraulic support
  - large processing range up to 300 mm<sup>2</sup>
  - 270° revolving quick-action crimping head
  - automatic pressure limitation and monitoring via pressure sensor
  - electronic control and monitoring of the crimping process
  - Saving of all crimping cycles and error messages to internal memory
  - Reading of all cycles and error messages via USB
  - Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

Type	ES EPG/HPG 60 DIN 6	Version
Order No.	<a href="#">2505280000</a>	Crimping tool insert, 6mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519662	
Qty.	1 ST	
Type	ES EPG 60/HPG DIN 10	Version
Order No.	<a href="#">2505290000</a>	Crimping tool insert, 10mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519723	
Qty.	1 ST	
Type	ES EPG 60/HPG DIN 16	Version
Order No.	<a href="#">2505300000</a>	Crimping tool insert, 16mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519709	
Qty.	1 ST	
Type	ES EPG 60/HPG DIN 25	Version
Order No.	<a href="#">2505310000</a>	Crimping tool insert, 25mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519693	
Qty.	1 ST	

## HPG 60

**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26  
D-32758 Detmold  
Germany

www.weidmueller.com

## Accessories

Type	ES EPG 60/HPG DIN 35	Version
Order No.	<a href="#">2505320000</a>	Crimping tool insert, 35mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519679	
Qty.	1 ST	
Type	ES EPG 60/HPG DIN 50	Version
Order No.	<a href="#">2505330000</a>	Crimping tool insert, 50mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519686	
Qty.	1 ST	
Type	ES EPG 60/HPG DIN 70	Version
Order No.	<a href="#">2505340000</a>	Crimping tool insert, 70mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519716	
Qty.	1 ST	
Type	ES EPG 60/HPG DIN 95	Version
Order No.	<a href="#">2505350000</a>	Crimping tool insert, 95mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519730	
Qty.	1 ST	
Type	ES EPG 60/HPG DIN 120	Version
Order No.	<a href="#">2505360000</a>	Crimping tool insert, 120mm <sup>2</sup> , Indent crimp
GTIN (EAN)	4050118519747	
Qty.	1 ST	

### ... for compression cable lugs



Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

### General ordering data

Type	ES EPG/HPG 60 HEX 6	Version
Order No.	<a href="#">2505150000</a>	Accessories, 6mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519532	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 10	Version
Order No.	<a href="#">2505160000</a>	Crimping tool insert, 10mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519556	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 16	Version
Order No.	<a href="#">2505170000</a>	Crimping tool insert, 16mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519549	
Qty.	1 ST	

## HPG 60

**Weidmüller Interface GmbH & Co. KG**  
 Klingenbergstraße 26  
 D-32758 Detmold  
 Germany

www.weidmueller.com

## Accessories

Type	ES EPG/HPG 60 HEX 25	Version
Order No.	<a href="#">2505180000</a>	Crimping tool insert, 25mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519570	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 35	Version
Order No.	<a href="#">2505190000</a>	Crimping tool insert, 35mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519587	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 50	Version
Order No.	<a href="#">2505200000</a>	Crimping tool insert, 50mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519600	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 70	Version
Order No.	<a href="#">2505210000</a>	Crimping tool insert, 70mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519594	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 95	Version
Order No.	<a href="#">2505220000</a>	Crimping tool insert, 95mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519563	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 120	Version
Order No.	<a href="#">2505230000</a>	Crimping tool insert, 120mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519624	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 150	Version
Order No.	<a href="#">2505240000</a>	Crimping tool insert, 150mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519631	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 185	Version
Order No.	<a href="#">2505250000</a>	Crimping tool insert, 185mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519617	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 240	Version
Order No.	<a href="#">2505260000</a>	Crimping tool insert, 240mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519648	
Qty.	1 ST	
Type	ES EPG/HPG 60 HEX 300	Version
Order No.	<a href="#">2505270000</a>	Crimping tool insert, 300mm <sup>2</sup> , Hexagonal crimp
GTIN (EAN)	4050118519655	
Qty.	1 ST	

## HPG 60

Weidmüller Interface GmbH &amp; Co. KG

Klingenbergstraße 26


D-32758 Detmold

Germany

www.weidmueller.com

## Accessories

## ... for wire-end ferrules

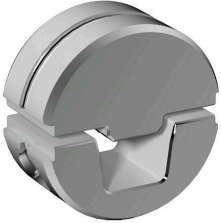

Crimping tools for cable lugs, connectors and wire-end ferrules with interchangeable inserts

- extremely fast processing thanks to hydraulic support
- large processing range up to 300 mm<sup>2</sup>
- 270° revolving quick-action crimping head
- automatic pressure limitation and monitoring via pressure sensor
- electronic control and monitoring of the crimping process
- Saving of all crimping cycles and error messages to internal memory
- Reading of all cycles and error messages via USB
- Li-ion rechargeable battery with charge status indicator: 18 V, 2 Ah

## General ordering data

Type	ES EPG 60/HPG AEH 25	Version
Order No.	<a href="#">2577810000</a>	Crimping tool insert, 25mm <sup>2</sup> , Trapezoidal crimp
GTIN (EAN)	4050118590722	
Qty.	1 ST	
Type	ES EPG 60/HPG AEH 50	Version
Order No.	<a href="#">2577830000</a>	Crimping tool insert, 50mm <sup>2</sup> , Trapezoidal crimp
GTIN (EAN)	4050118590708	
Qty.	1 ST	
Type	ES EPG 60/HPG AEH 70	Version
Order No.	<a href="#">2577850000</a>	Crimping tool insert, 70mm <sup>2</sup> , Trapezoidal crimp
GTIN (EAN)	4050118590692	
Qty.	1 ST	
Type	ES EPG 60/HPG AEH 95	Version
Order No.	<a href="#">2577870000</a>	Crimping tool insert, 95mm <sup>2</sup> , Trapezoidal crimp
GTIN (EAN)	4050118590685	
Qty.	1 ST	
Type	ES EPG 60/HPG AEH 120	Version
Order No.	<a href="#">2577880000</a>	Crimping tool insert, 120mm <sup>2</sup> , Trapezoidal crimp
GTIN (EAN)	4050118590678	
Qty.	1 ST	