

IE-C6GB8RB0200XCSXCS-E

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com



Assembled IE cables, railway cable, Cat.7, blue, M12

General ordering data

Version	, M12 X-type IP 67 straight male, M12 X-type IP 67 straight male, 20 m
Order No.	2464200200
Type	IE-C6GB8RB0200XCSXCS-E
GTIN (EAN)	4064675008798
Qty.	1 items

IE-C6GB8RB0200XCSXCS-E

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Approvals

ROHS	Conform
------	---------

Dimensions and weights

Length	20 m	Length (inches)	787.4016 inch
Net weight	1728 g		

Temperatures

Storage temperature	Operating temperature
Installation temperature	

Environmental Product Compliance

RoHS Compliance Status	Compliant with exemption
RoHS Exemption (if applicable/known)	6c
REACH SVHC	Lead 7439-92-1
SCIP	67cf1078-beca-4687-860b-dc475a6ec24a

Cable specific standards

Fluorine content	According to EN 60684-2 Section 45.2	Flames propagate vertically on bundled cables	in accordance with IEC 60332-1-2, EN 50305, According to IEC 60332-3-25 D, According to BS 6853 Appendix D, According to NF C32-070, 2.1, According to NF C32-070, 2.2, According to UL1685, 12 (FT4 exp.), in accordance with EN 50266
Corrosiveness of fumes	to IEC 60754-2	Fire safety for railway vehicles	According to EN 45545, HL1 - HL3, According to DIN 5510 1-4, According to UNI CEI 11170, LR1-LR4, According to NFPA 130, According to BS 6853, GM/RT 2130, Ia, Ib, II, According to NF F16-101, A1, A2, B
Impervious to smoke	According to BS 6853 Appendix D, According to IEC 61034-2, According to UL1685, 12 (FT4 exp.)	Poisonous gases	According to BS 6853 Appendix B

Cable structure

Strands	7	Sheathing colour	blue
Cross-section	4*2*AWG24/7 - 4*2*0.2 mm ²	Shielding	S/FTP
Sheath diameter, max.	8.6 mm	Sheath diameter, min.	7.6 mm

Mechanical and material properties of cable

Resistance to oils	Yes	Halogen	halogen-free, according to IEC 60754-2
Min. bending radius, repetitive	4 x cable diameter	Abrasion resistance	very good

IE-C6GB8RB0200XCSXCS-E

Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data

Resistance to spread of flame	einfügen EN60332	Corrosiveness of fumes	to IEC 60754-2
Impervious to smoke	According to BS 6853 Appendix D, According to IEC 61034-2, According to UL1685, 12 (FT4 exp.)		
Plug, left			
Plug left	M12, X-coded, IP67, male contact, straight, plug, Plastic, shielded		
Plug, right			
Plug right	M12, X-coded, IP67, male contact, straight, plug, Plastic, shielded		
Classifications			
ETIM 8.0	EC002599	ETIM 9.0	EC002599
ETIM 10.0	EC002599	ECLASS 14.0	27-06-03-08
ECLASS 15.0	27-06-03-08		

IE-C6GB8RB0200XCSXCS-E

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany


www.weidmueller.com

Drawings

Wiring

M12	1	White, Orange	1	M12
	2	Orange	2	
	3	White, Green	3	
	4	Green	4	
	5	White, Brown	5	
	6	Brown	6	
	7	White, Blue	7	
	8	Blue	8	

Pinning

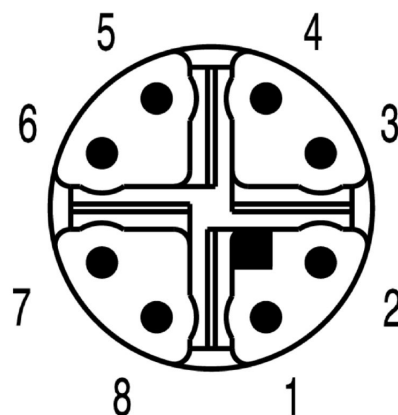

IE-C6GB8RB0200XCSXCS-E

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Screwty® cable gland tool



The ideal tool for any application

Screwty® is the ideal, all-purpose tool for tightening all common sensor and actuator cables. Even difficult-to-reach round plugs are accessible using the Screwty®. A simple turning movement tightens and loosens the connectors without the need for excessive force. The Screwty® is a unique and global solution since it fits with most cables and plugs from other vendors (over 90 %). The Screwty® consists of a handle with a conventional 1/4" adapter. Thus it can be used for all sizes: for M12 and M8 round plug-in connectors, and for M12F and M8F customisable plugs and sockets, as well as for all M23 plugs and sockets.

General ordering data

Type	SCREWTY SET	Version
Order No.	1910000000	Cable gland tool for M8, M12 lines and connectors
GTIN (EAN)	4032248436842	
Qty.	1 ST	

Screwty® cable gland tool with torque function



The ideal tool for any application

Screwty® is the ideal, all-purpose tool for tightening all common sensor and actuator cables. Even difficult-to-reach round plugs are accessible using the Screwty®. A simple turning movement tightens and loosens the connectors without the need for excessive force. The Screwty® is a unique and global solution since it fits with most cables and plugs from other vendors (over 90 %). The Screwty® consists of a handle with a conventional 1/4" adapter. Thus it can be used for all sizes: for M12 and M8 round plug-in connectors, and for M12F and M8F customisable plugs and sockets, as well as for all M23 plugs and sockets.

General ordering data

Type	SCREWTY SET -DM	Version
Order No.	1920000000	Cable gland tool for M8, M12 lines and connectors
GTIN (EAN)	4032248436859	
Qty.	1 ST	

IE-C6GB8RB0200XCSXCS-E

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Accessories

Screwty® cable gland tool



The ideal tool for any application

Screwty® is the ideal, all-purpose tool for tightening all common sensor and actuator cables. Even difficult-to-reach round plugs are accessible using the Screwty®. A simple turning movement tightens and loosens the connectors without the need for excessive force. The Screwty® is a unique and global solution since it fits with most cables and plugs from other vendors (over 90 %). The Screwty® consists of a handle with a conventional 1/4" adapter. Thus it can be used for all sizes: for M12 and M8 round plug-in connectors, and for M12F and M8F customisable plugs and sockets, as well as for all M23 plugs and sockets.

General ordering data

Type	SCREWTY- M12	Version
Order No.	1900000000	Cable gland tool for moulded M12 lines
GTIN (EAN)	4032248375868	
Qty.	1 ST	

Screwty® cable gland tool with torque function



The ideal tool for any application

Screwty® is the ideal, all-purpose tool for tightening all common sensor and actuator cables. Even difficult-to-reach round plugs are accessible using the Screwty®. A simple turning movement tightens and loosens the connectors without the need for excessive force. The Screwty® is a unique and global solution since it fits with most cables and plugs from other vendors (over 90 %). The Screwty® consists of a handle with a conventional 1/4" adapter. Thus it can be used for all sizes: for M12 and M8 round plug-in connectors, and for M12F and M8F customisable plugs and sockets, as well as for all M23 plugs and sockets.

General ordering data

Type	SCREWTY-M12-DM	Version
Order No.	1900001000	Cable gland tool for moulded M12 lines
GTIN (EAN)	4032248436408	
Qty.	1 ST	